



SC CABLE SNAP CLIP



FEATURES

Easily supports cable and plastic conduit from flanges

Requires only a hammer to install

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	Article Number	Flange Thickness (FT)	Outer Diameter (OD)	Thickness (T)	Packing Quantity
24SC1011	187550	2 - 4 mm	10 - 11 mm	0.6 mm	1.0000
24SC1214	187570	2 - 4 mm	12 - 14 mm	0.6 mm	1.0000
24SC1214R25	191002	2 - 4 mm	12 - 14 mm	0.6 mm	25.0000
24SC1518	187590	2 - 4 mm	15 - 18 mm	0.6 mm	1.0000
24SC1518R25	191003	2 - 4 mm	15 - 18 mm	0.6 mm	25.0000
24SC1924	187610	2 - 4 mm	19 - 24 mm	0.6 mm	1.0000
24SC1924R25	191004	2 - 4 mm	19 - 24 mm	0.6 mm	25.0000
24SC2530	187630	2 - 4 mm	25 - 32 mm	0.6 mm	1.0000
24SC2530R25	191005	2 - 4 mm	25 - 32 mm	0.6 mm	25.0000
24SC67	187510	2 - 4 mm	6 - 7 mm	0.6 mm	1.0000
24SC78	187710	2 - 4 mm	7 - 8 mm	0.6 mm	1.0000

CatalogNumber	Article Number	Flange Thickness (FT)	OuterDiameter (OD)	Thickness (T)	Packing Quantity
24SC89	187530	2 - 4 mm	8 - 9 mm	0.6 mm	1.0000
24SC910	187750	2 - 4 mm	9 - 10 mm	0.6 mm	1.0000
47SC1011	187540	4 - 7 mm	10 - 11 mm	0.6 mm	1.0000
47SC1214	187560	4 - 7 mm	12 - 14 mm	0.6 mm	1.0000
47SC1518	187580	4 - 7 mm	15 - 18 mm	0.6 mm	1.0000
47SC1518R25	191009	4 - 7 mm	15 - 18 mm	0.6 mm	25.0000
47SC1924	187600	4 - 7 mm	19 - 24 mm	0.6 mm	1.0000
47SC1924R25	191010	4 - 7 mm	19 - 24 mm	0.6 mm	25.0000
47SC2530	187620	4 - 7 mm	25 - 32 mm	0.6 mm	1.0000
47SC2530R25	191011	4 - 7 mm	25 - 32 mm	0.6 mm	25.0000
47SC67	187500	4 - 7 mm	6 - 7 mm	0.6 mm	1.0000
47SC78	187720	4 - 7 mm	7 - 8 mm	0.6 mm	1.0000
47SC89	187520	4 - 7 mm	8 - 9 mm	0.6 mm	1.0000
47SC910	187760	4 - 7 mm	9 - 10 mm	0.6 mm	1.0000
812SC1011	187660	8 - 12 mm	10 - 11 mm	0.6 mm	1.0000
812SC1214	187670	8 - 12 mm	12 - 14 mm	0.6 mm	1.0000
812SC1518	187680	8 - 12 mm	15 - 18 mm	0.6 mm	1.0000
812SC1518R25	191015	8 - 12 mm	15 - 18 mm	0.6 mm	25.0000
812SC1924	187690	8 - 12 mm	19 - 24 mm	0.6 mm	1.0000
812SC1924R25	191016	8 - 12 mm	19 - 24 mm	0.6 mm	25.0000
812SC2530	187700	8 - 12 mm	25 - 32 mm	0.6 mm	1.0000
812SC2530R25	191017	8 - 12 mm	25 - 32 mm	0.6 mm	25.0000
812SC67	187640	8 - 12 mm	6 - 7 mm	0.6 mm	1.0000
812SC78	187730	8 - 12 mm	7 - 8 mm	0.6 mm	1.0000
812SC89	187650	8 - 12 mm	8 - 9 mm	0.6 mm	1.0000
812SC910	187770	8 - 12 mm	9 - 10 mm	0.6 mm	1.0000

DIAGRAMS

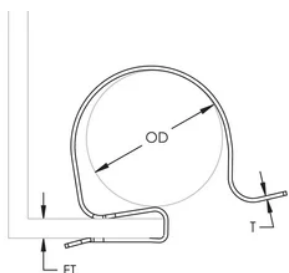

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER