



STRUT BEAM CLIP



FEATURES

Beam Clip for clamping the open side of strut to a beam

Suitable for all strut channels

Requires installation in pairs

Structural attachment to beams to support nVent CADDY Eristrut

FM® Specification Tested

SPECIFICATIONS

Finish: Hot-Dip Galvanized

Table 1/2

Catalog Number	Article Number	Material	Flange Thickness (FT)	Hole Size (HS)	Length (L)	Thickness (T)
ZT605HD	313260	Steel	16 mm Max	13 mm	49 mm	6 mm
ZTA605	388080	Steel	16 mm Max	13 mm	49 mm	6 mm
ZTA605S6	387190	Stainless Steel 316 (EN 1.4401)	16 mm Max	13 mm	49 mm	6 mm

Table 2/2


Catalog Number	Article Number	Width (W)	Static Load (F)	Screw Included
ZT605HD	313260	40 mm	2040N	Yes
ZTA605	388080	40 mm	2040N	No

Catalog Number	Article Number	Width (W)	Static Load (F)	Screw Included
ZTA605S6	387190	40 mm	2040N	No

ADDITIONAL PRODUCT DETAILS

Indicated loads are based on installation with 1/2" (M12) hardware and strut channel type A.

DIAGRAMS

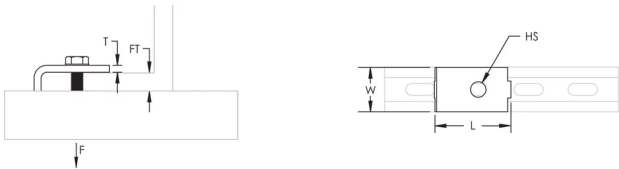

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	Europe Netherlands: +31 800-0200135 France: +33 800 901 793	Europe Germany: 800 1890272 Other Countries: +31 13 5835404	APAC Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--