

## TBHKM TRAPEZOIDAL DECK HANGER WITH FIXED NUT



### CERTIFICATIONS



### FEATURES

Requires separate cross bolt and nut

Use TDHP perforation tool to punch hole in decking

### SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2

Catalog Number	Article Number	Rod Size (RS)	A	B	C	Thickness (T)
TBHKM10	597583	10	97 mm	91.5 mm	25 mm	2.5 mm
TBHKM8	597582	8	97 mm	91.5 mm	25 mm	2.5 mm


Table 2/2

Catalog Number	Article Number	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Certifications
----------------	----------------	-------------------	-------------------	----------------

TBHKM10	597583	10.5 mm	5 mm	FM Approved, Pipe Hanger Components, ITB, VdS G4060082
TBHKM8	597582	10.5 mm	5 mm	ITB, VdS G4060082

Ceiling Thickness	Static Load F
0,63 mm - 0,70 mm	600 N
0,71 mm - 0,80 mm	700 N
0,81 mm - 1,00 mm	800 N
1,01 mm - 1,20 mm	1000 N
1,21 mm - 1,50 mm	1200 N
> 1,50 mm	1500 N

### DIAGRAMS

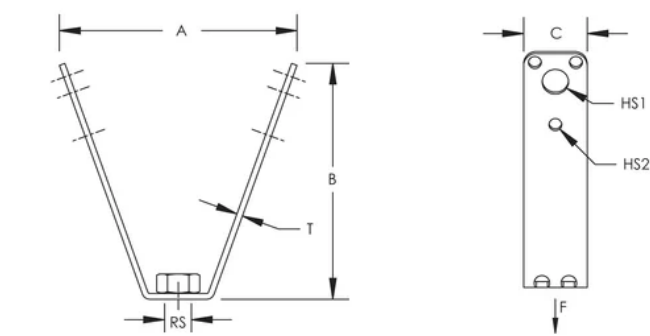

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**