




TELESCOPING SCREW GUN BOX BRACKET

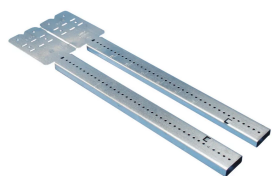

CERTIFICATIONS



FEATURES

- Can mount multiple boxes
- Notched and marked for easy identification and bending
- Improved design with stamped inch markings and pilot holes accelerates precise box conduit mounting between studs
- Pilot holes allow easy box attachment with a screwdriver
- Requires only a screw gun to install
- Can be mounted to face or inside of stud
- Adjustable for non-standard stud spacing
- Interlocking tab prevents accidental disassembly
- Unique, one-piece, break apart design

SPECIFICATIONS

- Finish:** Pregalvanized
- Material:** Steel

Table 1/1				
Catalog Number	Article Number	Stud Spacing	Box Depth	Packing Quantity

TSGB16	187190	280 - 458 mm	38mm, 54mm	1.0000
TSGB1624	187199	400 - 635 mm	38mm, 54mm, 63.5mm	1.0000
TSGB24	187191	432 - 660 mm	38mm, 54mm, 63.5mm	1.0000

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER