



# UNIVERSAL RESTRAINT CLIP, SLOTTED



## CERTIFICATIONS



## FEATURES

Slotted design ideal for attaching to existing threaded rod on trapezes

Meets CEN/TS 17551:2021 requirements for Seismic Sway Bracing

## SPECIFICATIONS

**Finish:** Electrogalvanized  
**Material:** Steel

Table 1/1


Catalog Number	Article Number	Brace Size	Rod Size (RS)	Thickness (T)
CSBURCR12	402202	#12, #18	12	4.27 mm
CSBURCR38	402201	#12, #18	10	4.27 mm
CSBURCR58	402203	#12, #18	16	4.27 mm

## ADDITIONAL PRODUCT DETAILS

Brace member is not included.

UL Loads		
Part Number	Brace Member	Load Rating
CSBURCR38	CSB12CBL	1859 N
	CSB18CBL	3434 N
CSBURCR12	CSB12CBL	1859 N
	CSB18CBL	3434 N
CSBURCR58	CSB12CBL	1859 N
	CSB18CBL	3434 N

### DIAGRAMS

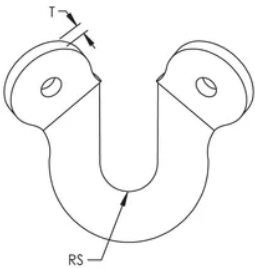

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com**   **CADDY**   **ERICO**   **HOFFMAN**   **RAYCHEM**   **SCHROFF**  
**TRACER**