


## CABLE TO WEB OF RAIL MOLD PAIR, POWER

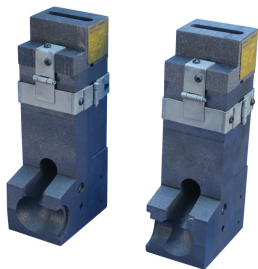

### FEATURES

Replacement mold pair designed for the installation of track circuits and jumper bonds to the neutral axis

Sold in pairs

### SPECIFICATIONS

**Material:** Graphite

**Bond Terminal Style:** W

Table 1/1

Catalog Number	Rail Type	Handle Clamp	Conductor Outer Diameter, Nominal	Welder Style	Welding Material	Conductor Size
PBWX201	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	7.75mm	T20	PB45, Sold Separately	35 mm <sup>2</sup> Ropelay
PBWX301	UIC60	C105C, Sold Separately	8.89mm	T20	PB65, Sold Separately	50 mm <sup>2</sup> Concentric
PBWX3	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	9.13mm	T20	PB65, Sold Separately	50 mm <sup>2</sup> Ropelay
PBW2C	85 lb to 141 lb T-Rail Sections		9.47mm	T20	PB65, Sold Separately	1/0 Concentric
PBW2G	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	10.62mm	T20	PB90, Sold Separately	2/0 Concentric
PBW2E	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	10.87mm	T20	PB65, Sold Separately	1/0 Ropelay

Catalog Number	Rail Type	Handle Clamp	Conductor Outer Diameter, Nominal	Welder Style	Welding Material	Conductor Size
PBW2J	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	12.19mm	T20	PB90, Sold Separately	2/0 Ropelay
PBWX5	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	12.83mm	T20	PB90, Sold Separately	95 mm <sup>2</sup> Ropelay
PBW2Q	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	13.41mm	T20	PB90, Sold Separately	4/0 Concentric
PBW9F	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	14.53mm	T20	PB115 or PB115PLUSF80, Sold Separately	19/#9 Copperweld
PBW2S	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	15.49mm	T20	PB90, Sold Separately	4/0 Ropelay
PBXLWX5	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	15.52mm	T20	PB90, Sold Separately	95 mm <sup>2</sup> Ropelay
PBWX7	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	16mm	T20	PB200, Sold Separately	150 mm <sup>2</sup> Ropelay
PBWS7	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	16.66mm	T20	PB250 or PB250PLUSF80, Sold Separately	4/0 Composite
PBW3D	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	17.3mm	T20	PB150 or PB150PLUSF80, Sold Separately	350 kcmil Concentric
PBWX8	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	17.8mm	T20	PB200, Sold Separately	185 mm <sup>2</sup> Ropelay
PBW2W	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	19.05mm	T20	PB115, Sold Separately	250 kcmil Ropelay
PBW2W135	135 lb Bethlehem	C105C, Sold Separately	19.05mm	T20	PB115, Sold Separately	250 kcmil Ropelay
PBW2W20AS	20 lb ASCE	C105C, Sold Separately	19.05mm	T20	PB115, Sold Separately	250 kcmil Ropelay
PBW2W40AS	40 lb ASCE	C105C, Sold Separately	19.05mm	T20	PB115, Sold Separately	250 kcmil Ropelay
PBW3B	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	20.32mm	T20	PB150 or PB150PLUSF80, Sold Separately	300 kcmil Ropelay
PBW3S	85 lb to 141 lb T-Rail Sections	C105C, Sold Separately	26.42mm	T20	PB250, Sold Separately	500 kcmil Ropelay
PBW3SZU160	ZU160 Rail	C105C, Sold Separately	26.42mm	T20	PB250 or PB250PLUSF80, Sold Separately	500 kcmil Ropelay

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**