


MS PDU, 2U, 60A(48A)NA/63A INT, 208V NA, 230V INT, 1P, 4 CB, (6)C13, (6)4-IN-1

CATALOG NUMBER

EN2355

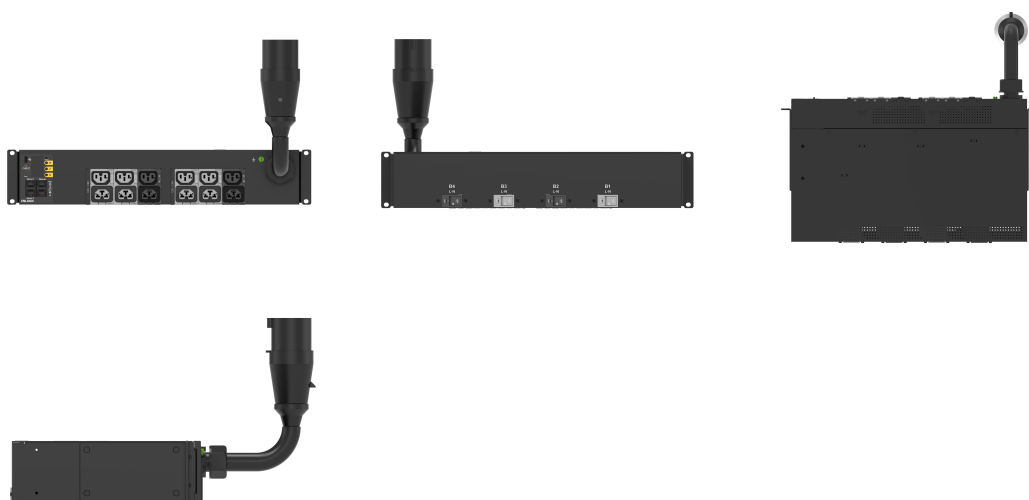

The Advantage Series Input Metered, Outlet Switched PDU family offers energy metering with advanced power and environmental monitoring options and remote outlet on/off switching. Comprehensive monitoring at both the input phase and circuit breaker levels offers advanced alerts of potential overloads. Billing-grade metering provides accurate power consumption data for energy use optimization. The hot-swappable network management controller features Gigabit and redundant ethernet communication with advanced support for external environmental sensors and rack security access solutions.

PRODUCT ATTRIBUTES

Socket Type: (6) C13/C15; (6) C13/C15/C19/C21

Color: Black

Switched Outlets: Yes

Circuit Breaker: 20 A

Circuit Breaker Quantity: 4

Input Voltage: 208 VAC, 1 PH

Interrupt Rating: 5kAIC

Nominal Voltage: 230V

Number of Poles: 1

Output Voltage: 208 – 230VAC

Plug Type: IEC 60309 360P6 (IP44)

Rack Units: 2U

Removable Input Cable: No

Product Type: Socket Strip

Product Family: Enlogic

Type: Intelligent PDU

Finish: Powder Coated

Material: Steel

Height: 87mm

Width: 444mm

Depth: 269mm

Weight: 8kg

Package Quantity: 1

Length: 87mm

Input Cable Length: 3m

ADDITIONAL PRODUCT DETAILS

87 mm L x 444 mm W x 269 mm D, (269 mm D at CB)

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER