


527 PARALLEL CABLE CONNECTOR

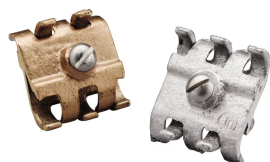

CERTIFICATIONS



FEATURES

Cable splice with positive single bolt tension grip on cable or wire


For use with all full size cables on Class I/II structures

SPECIFICATIONS

Table 1/1

Catalog Number	Conductor Size, UL	Material	Depth (D)	Width (W)	Unit Weight
LPC527	Class 1 - Class 2 (4/0 Max)	Bronze	51.31mm	50.8 mm	0.16 kg

DIAGRAMS

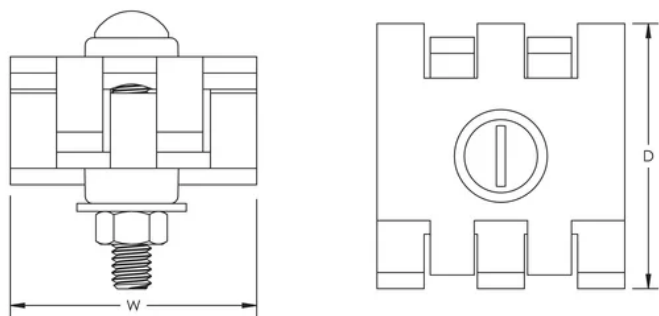

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER