

AIR TERMINAL BASE ROUND CONDUCTOR, METRIC THREAD



CERTIFICATIONS



FEATURES

Cast air terminal base for mounting on horizontal surfaces to be used in conjunction with lightning protection conductors

SPECIFICATIONS

Material: Bronze

Table 1/2


Catalog Number	Complies With	Conductor Size	A	Thread Length (TL)	Height (H)	Hole Size (HS)
ATBCR050	EN IEC® 62561-1 Class H 100kA	50 mm ² Stranded	80 mm	20mm	48.5 mm	6.6 mm
ATBCR070	EN IEC® 62561-1 Class H 100kA	70 mm ² Stranded	80 mm	20mm	50.5 mm	6.6 mm
ATBCR095	EN IEC® 62561-1 Class H 100kA	95 mm ² Stranded	80 mm	20mm	52.5 mm	6.6 mm

Table 2/2

Catalog Number	Thread Size (TS)	Unit Weight
ATBCR050	M16	0.67 kg

Catalog Number	Thread Size (TS)	Unit Weight
ATBCR070	M16	0.67 kg
ATBCR095	M16	0.67 kg

DIAGRAMS

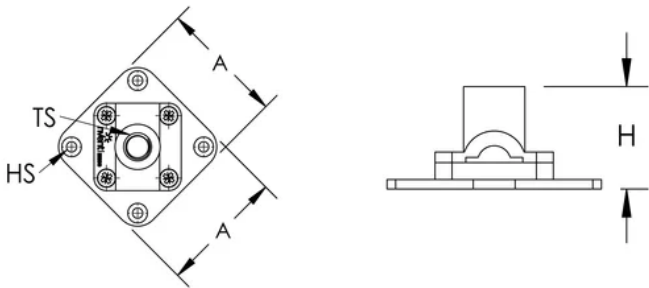

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500