

## GALVANIZED GROUND ROD, POINTED



### CERTIFICATIONS



### FEATURES

Meets ANSI®/NEMA® GR1

Zinc-coated exteriors are hot-dip galvanized for solid protection against corrosion, in accordance with ASTM® specification A123

Surfaces are rigidly inspected to eliminate seams, slivers and other defects

### SPECIFICATIONS


Table 1/2

Catalog Number	Material	Finish	Tensile Strength	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Length (L)
815800	Steel	Hot-Dip Galvanized	552 MPa Min	5/8"	16 mm	3.05 m

Table 2/2

Catalog Number	Unit Weight	UPC Label
815800	4.8 kg	No

DIAGRAMS

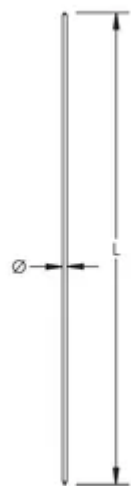

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**