

# NVENT ERICO SYSTEM 3000 INTERCEPTOR



## CERTIFICATIONS



## FEATURES

Dynamic response to the approach of a lightning downleader

Designed for lower height installations

Non-radioactive technology

No external power required

## SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Temperature	Installation Height (H)	Diameter 1 (Ø1)	Diameter 2 (Ø2)
INTMKIVSS	702089	Stainless Steel 316 (EN 1.4401)	-40 to 100 °C	20 m Max	101.6 mm	26.15 mm

Table 2/2

Catalog Number	Article Number	Height (H)	Thread Size (TS)	Unit Weight
INTMKIVSS	702089	348 mm	1/2" BSPP	2.06 kg

DIAGRAMS

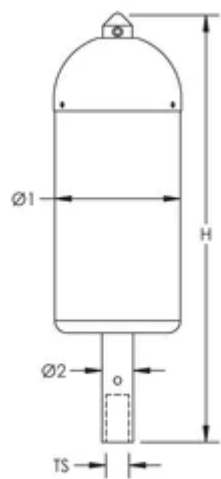

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500