

## SURGE COUNTER, DIGITAL DISPLAY



### FEATURES

Records time and date of transient surge events


Resettable counter

Snap on, hall effect transducer

### SPECIFICATIONS

Catalog Number	DSCL2
Trip Threshold	100
Status Indication	LCD
Connection, Stranded	50 mm <sup>2</sup> Max
Lead Length	50.8mm
Enclosure Material	UL® 94V-0 Thermoplastic
Enclosure Rating	IP 20 NEMA®-1
Mounting	35 mm top hat DIN rail
Temperature	-20 to 70 °C
Module Width	2 M
Depth (D)	68mm
Height (H)	90 mm
Width (W)	36 mm
Unit Weight	190 kg

DIAGRAMS

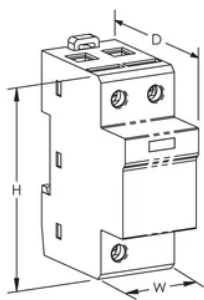

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**