


# CABS BUSBAR SUPPORT KIT

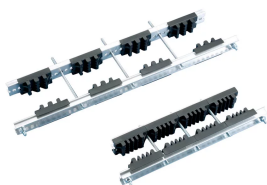

## CERTIFICATIONS



## FEATURES

For all busbar types

Improve bending resistance by interlocking or stacking two profiles

Quick and easy to install

Halogen free insulators

RoHS compliant

## SPECIFICATIONS

<b>Typical Application Current Rating:</b>	400 - 4500 A
<b>Max Working Voltage, IEC (Ui):</b>	1000;1500
<b>Material:</b>	Aluminum;Glass Fibre Reinforced Polyamide;Steel
<b>Finish:</b>	Electrogalvanized
<b>Complies With:</b>	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
<b>Flammability Rating:</b>	UL® 94V-0
<b>Working Temperature:</b>	-40 to 130 °C

Table 1/2


Catalog Number	Article Number	Busbars per Phase	Busbar Width	Busbar Thickness	Depth (D)	Width (W)
----------------	----------------	-------------------	--------------	------------------	-----------	-----------

CABS4-5TN-400	549310	1 - 4	30 - 125 mm	5 mm	39mm	350 mm
CABS4-5TN-600	549260	1 - 4	30 - 125 mm	5 mm	39mm	550 mm
CABS2-10TN-400	549320	1 - 2	30 - 120 mm	10 mm	39mm	350 mm
CABS2-10TN-600	549270	1 - 2	30 - 120 mm	10 mm	39mm	550 mm

Table 2/2

Catalog Number	Article Number	A	B	C	Unit Weight
CABS4-5TN-400	549310	300 mm	75 mm	325 mm	0.8 kg
CABS4-5TN-600	549260	500 mm	75 - 125 mm	525 mm	0.84 kg
CABS2-10TN-400	549320	300 mm	75 mm	325 mm	0.77 kg
CABS2-10TN-600	549270	500 mm	75 - 125 mm	525 mm	0.81 kg

## DIAGRAMS

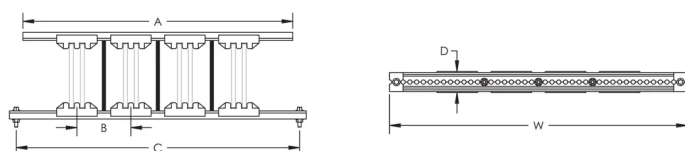

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**