

## DRG ASYMMETRIC PROFILE



### CERTIFICATIONS



### FEATURES

Rapid assembly of all kinds of frameworks

High mechanical resistance

High corrosion resistance

Conforms to EN 60715 and 50035 and DIN 46277

RoHS compliant

### SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2


Catalog Number	Article Number	Height (H)	Width (W)	Length (L)	Thickness (T)	A
DRG2M	558000	32 mm	15 mm	2000 mm	1.5 mm	9 mm
DRG3M	558010	32 mm	15 mm	3000 mm	1.5 mm	9 mm

Table 2/2

Catalog Number	Article Number	Unit Weight
----------------	----------------	-------------

DRG2M	558000	1.4 kg
DRG3M	558010	2.1 kg

DIAGRAMS

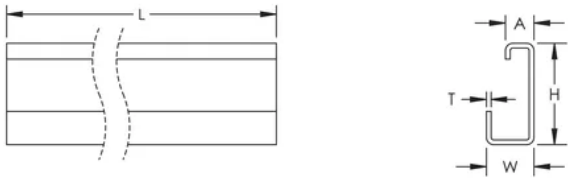

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500