

NVENT ERIFLEX FLEXBUS TRANSFORMER COVER IP2X FOR 2 CONDUCTORS PER PHASE



CERTIFICATIONS



FEATURES

Input/output for neutral/ground conductor

Resistance to solvent and hydrocarbon splashes

Installs quickly and easily

UV resistance

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Working Temperature	Length (L)	Width (W)	Depth (D)
FLEXCOVIP2XTWO	508161	Polyvinylchloride	-40 to 140 °C	670 mm	230 mm	180mm

Table 2/2

Catalog Number	Article Number	Unit Weight
FLEXCOVIP2XTWO	508161	0.84 kg

DIAGRAMS

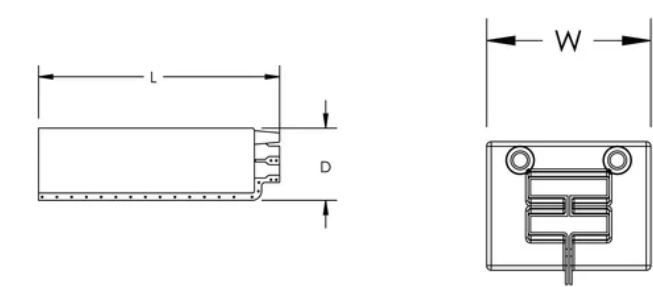

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	Europe Netherlands: +31 800-0200135 France: +33 800 901 793	Europe Germany: 800 1890272 Other Countries: +31 13 5835404	APAC Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--