

TRC FOUR POLE DISTRIBUTION BLOCK, 400 A



CERTIFICATIONS



FEATURES

- Transparent protection cover
- Bolts included for output connections
- Easy accessibility for wiring
- Ready to use out of the box, saving installation time and labor
- RoHS compliant

SPECIFICATIONS

Catalog Number	TRC-400A
Article Number	563180
Material	Copper Glass Fibre Reinforced Polyamide Plexiglass
Max Working Voltage, IEC (Ui)	1000
Peak Short Circuit Current (Ipk)	118kA
Short Term Withstand Current (Icw) 1s	28kA
Line Side Number of Connections	1
Load Side Number of Connections	10


Catalog Number	TRC-400A
Thread Size 1 (TS1)	M6
Thread Size 2 (TS2)	M10
Depth (D)	50mm
Height (H)	338 - 390 mm
Width (W)	260 mm
A	290 mm
Unit Weight	2.65 kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

ADDITIONAL PRODUCT DETAILS

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

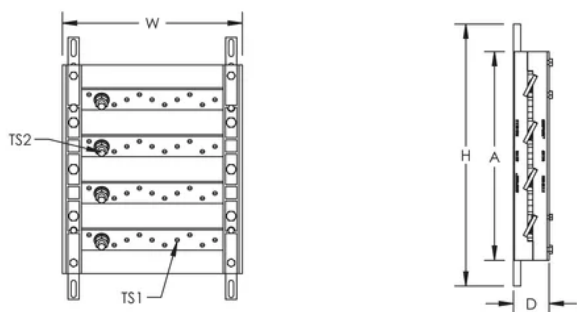

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER