


BARRIER KITS BRACKET-MOUNTED

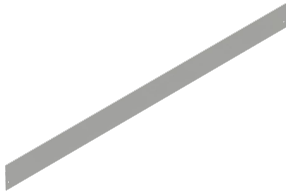

Divides wireway into two or three compartments. Plated spring steel brackets hold barriers in place by friction fit inside wireway. Order barrier and bracket separately. Recommended spacing increments of 3 ft.

FEATURES

Divides wireway into two or three compartments

Plated spring steel brackets hold barriers in place by friction fit inside wireway

Order barrier and bracket separately. Recommended spacing increments of 3 feet

SPECIFICATIONS

Color Code:	ANSI 61
Finish:	Galvanized; Powder Coated
Color:	Gray
Material:	Mild Steel

Table 1/1

Catalog Number	Article Number	Type	Height	Width	Depth	Thickness
F44BB2C	20270	Barrier Kit	102mm	102mm	25mm	1.9mm
F66BB2C	20300	Barrier Kit	152mm	152mm	25mm	1.9mm
F44BB3C	20290	Barrier Kit	102mm	102mm		1.9mm
F44B360	20320	Barrier Kit	102mm	102mm	1524mm	1.9mm
F66B560	20340	Barrier Kit	152mm	152mm	3048mm	1.9mm
F66BB3C	20310	Barrier Kit	152mm	152mm		1.9mm

ADDITIONAL PRODUCT DETAILS

Sealing Plates package consists of five barriers or five brackets. Each barrier is 60 inches long.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER