


## FRONT PANEL, SHIELDED, BOTTOM HINGED

U-profile front panel bottom hinged for textile gasket.

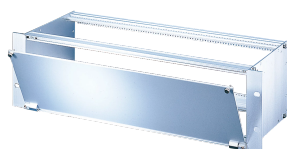

### CERTIFICATIONS



### FEATURES

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for subracks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

### SPECIFICATIONS

Table 1/3

| Catalog Number | EMC Gasket Type | Treated Edges | Front Finish | Rear Finish | EMC Shielding      | Rack Width |
|----------------|-----------------|---------------|--------------|-------------|--------------------|------------|
| 20848-599      | Textile         | No            | Anodized     | Conductive  | No (Retrofittable) | 42 HP      |
| 20848-600      | Textile         | No            | Anodized     | Conductive  | No (Retrofittable) | 63 HP      |
| 20848-601      | Textile         | No            | Anodized     | Conductive  | No (Retrofittable) | 84 HP      |
| 20848-602      | Textile         | No            | Anodized     | Conductive  | No (Retrofittable) | 42 HP      |

| Catalog Number | EMC Gasket Type | Treated Edges | Front Finish | Rear Finish | EMC Shielding      | Rack Width |
|----------------|-----------------|---------------|--------------|-------------|--------------------|------------|
| 20848-603      | Textile         | No            | Anodized     | Conductive  | No (Retrofittable) | 63 HP      |
| 20848-604      | Textile         | No            | Anodized     | Conductive  | No (Retrofittable) | 84 HP      |
| 20848-605      | Textile         | No            | Anodized     | Conductive  | No (Retrofittable) | 42 HP      |
| 20848-606      | Textile         | No            | Anodized     | Conductive  | No (Retrofittable) | 63 HP      |
| 20848-607      | Textile         | No            | Anodized     | Conductive  | No (Retrofittable) | 84 HP      |
| 20848-608      | Textile         | No            | Anodized     | Conductive  | No (Retrofittable) | 28 HP      |
| 20848-696      | Textile         | No            | Anodized     | Conductive  | No (Retrofittable) | 28 HP      |

| Table 2/3      |                  |          |              |                            |             |          |
|----------------|------------------|----------|--------------|----------------------------|-------------|----------|
| Catalog Number | Package Quantity | Height   | Product Type | Type                       | Rack Height | Width    |
| 20848-599      | 1                | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 213 mm   |
| 20848-600      | 1                | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 319.7 mm |
| 20848-601      | 1                | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 426.4 mm |
| 20848-602      | 1                | 261.8 mm | Front Panel  | Front Panel without Handle | 6 U         | 213 mm   |
| 20848-603      | 1                | 261.8 mm | Front Panel  | Front Panel without Handle | 6 U         | 319.7 mm |
| 20848-604      | 1                | 261.8 mm | Front Panel  | Front Panel without Handle | 6 U         | 426.4 mm |
| 20848-605      | 1                | 172.9 mm | Front Panel  | Front Panel without Handle | 4 U         | 213 mm   |
| 20848-606      | 1                | 172.9 mm | Front Panel  | Front Panel without Handle | 4 U         | 319.7 mm |
| 20848-607      | 1                | 172.9 mm | Front Panel  | Front Panel without Handle | 4 U         | 426.4 mm |
| 20848-608      | 1                | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 141.9 mm |
| 20848-696      | 1                | 261.8 mm | Front Panel  | Front Panel without Handle | 6 U         | 141.9 mm |

Table 3/3

| Catalog Number | Complies With                   | Mounting       | Material |
|----------------|---------------------------------|----------------|----------|
| 20848-599      | IEC 60297-3-101, IEEE 1101.1/10 | Hinged, Bottom | Aluminum |
| 20848-600      | IEC 60297-3-101, IEEE 1101.1/10 | Hinged, Bottom | Aluminum |
| 20848-601      | IEC 60297-3-101, IEEE 1101.1/10 | Hinged, Bottom | Aluminum |
| 20848-602      | IEC 60297-3-101, IEEE 1101.1/10 | Hinged, Bottom | Aluminum |
| 20848-603      | IEC 60297-3-101, IEEE 1101.1/10 | Hinged, Bottom | Aluminum |
| 20848-604      | IEC 60297-3-101, IEEE 1101.1/10 | Hinged, Bottom | Aluminum |
| 20848-605      | IEC 60297-3-101, IEEE 1101.1/10 | Hinged, Bottom | Aluminum |
| 20848-606      | IEC 60297-3-101, IEEE 1101.1/10 | Hinged, Bottom | Aluminum |
| 20848-607      | IEC 60297-3-101, IEEE 1101.1/10 | Hinged, Bottom | Aluminum |
| 20848-608      | IEC 60297-3-101, IEEE 1101.1/10 | Hinged, Bottom | Aluminum |
| 20848-696      | IEC 60297-3-101, IEEE 1101.1/10 | Hinged, Bottom | Aluminum |

## ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**