


NOVASTAR 19" PANEL/SLIDE MOUNT

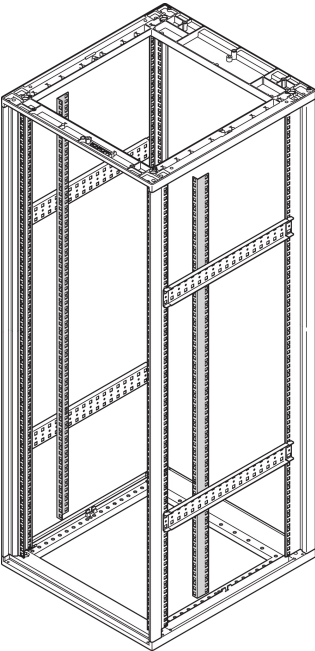

Novastar 19" Panel/Slide Mount Kit with load capacity of 400 kg, ensures easy fitting of 19" components to depth members.

CERTIFICATIONS



FEATURES

- For recessed installation of 19" components
- For fitting to depth members (25 mm grid)
- Load carrying capacity 400 kg

SPECIFICATIONS

Table 1/2						
Catalog Number	Package Quantity	Package Unit	Height	Product Type	Product Family	Rack Height
27230-172	1	Pair	267.1 mm	Slide Mount	Novastar	6 U

Catalog Number	Package Quantity	PackageUnit	Height	ProductType	Product Family	Rack Height
27230-173	1	Pair	400.45 mm	Slide Mount	Novastar	9 U
27230-174	1	Pair	533.8 mm	Slide Mount	Novastar	12 U
27230-175	1	Pair	711.6 mm	Slide Mount	Novastar	16 U
27230-176	1	Pair	889.4 mm	Slide Mount	Novastar	20 U
27230-177	1	Pair	1111.65 mm	Slide Mount	Novastar	25 U
27230-178	1	Pair	1511.7 mm	Slide Mount	Novastar	34 U
27230-179	1	Pair	1689.5 mm	Slide Mount	Novastar	38 U
27230-180	1	Pair	1911.75 mm	Slide Mount	Novastar	43 U
27230-181	1	Pair	2089.55 mm	Slide Mount	Novastar	47 U

Table 2/2

Catalog Number	Color	Color Code
27230-172	Black Grey	RAL 7021
27230-173	Black Grey	RAL 7021
27230-174	Black Grey	RAL 7021
27230-175	Black Grey	RAL 7021
27230-176	Black Grey	RAL 7021
27230-177	Black Grey	RAL 7021
27230-178	Black Grey	RAL 7021
27230-179	Black Grey	RAL 7021
27230-180	Black Grey	RAL 7021
27230-181	Black Grey	RAL 7021

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER