

19" FRONT PANEL

Front panels are Al anodized, colours light grey (RAL 7035) or black grey (RAL 7021).



CERTIFICATIONS



FEATURES

Al anodized, 3 mm

SPECIFICATIONS

Accessory Type: Front panel

Table 1/3

Catalog Number	Type	Mounting	EMC Shielding	Material	Front Finish	Rear Finish
30118-948	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-299	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30219-098	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
40304-074	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
30118-950	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-302	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30219-104	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized

Catalog Number	Type	Mounting	EMC Shielding	Material	Front Finish	Rear Finish
40304-076	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
30118-951	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-303	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30219-107	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
40304-077	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
30118-953	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-305	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30219-113	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
40304-079	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
30118-954	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-306	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30219-137	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
40304-080	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
30118-956	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-308	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30219-143	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
40304-082	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
30118-301	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-304	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-307	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-309	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-949	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-952	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-955	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30118-957	19" Front Panel	Screw-on Front	No	Aluminum	Painted	Painted
30219-101	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
30219-110	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
30219-138	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
30219-144	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
40304-075	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
40304-078	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
40304-081	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized
40304-083	19" Front Panel	Screw-on Front	No	Aluminum	Anodized	Anodized

Table 2/3

Catalog Number	Treated Edges	Color Code	Rack Height	Height (H)	Rack Width	Width (W)
30118-948		RAL 7021	1U	43.6mm	95HP	483mm
30118-299		RAL 7035	1U	43.6mm	95HP	483mm
30219-098	No		1U	43.6mm	95HP	483mm
40304-074	Yes		1U	43.6mm	95HP	483mm
30118-950		RAL 7021	3U	132.5mm	95HP	483mm
30118-302		RAL 7035	3U	132.5mm	95HP	483mm
30219-104	No		3U	132.5mm	95HP	483mm
40304-076	Yes		3U	132.5mm	95HP	483mm
30118-951		RAL 7021	4U	177mm	95HP	483mm
30118-303		RAL 7035	4U	177mm	95HP	483mm
30219-107	No		4U	177mm	95HP	483mm
40304-077	Yes		4U	177mm	95HP	483mm
30118-953		RAL 7021	6U	265.9mm	95HP	483mm
30118-305		RAL 7035	6U	265.9mm	95HP	483mm
30219-113	No		6U	265.9mm	95HP	483mm
40304-079	Yes		6U	265.9mm	95HP	483mm
30118-954		RAL 7021	7U	310.3mm	95HP	483mm
30118-306		RAL 7035	7U	310.3mm	95HP	483mm
30219-137	No		7U	310.3mm	95HP	483mm
40304-080	Yes		7U	310.3mm	95HP	483mm
30118-956		RAL 7021	9U	399.2mm	95HP	483mm
30118-308		RAL 7035	9U	399.2mm	95HP	483mm
30219-143	No		9U	399.2mm	95HP	483mm
40304-082	Yes		9U	399.2mm	95HP	483mm
30118-301		RAL 7035	2U	88.1mm	95HP	483mm
30118-304		RAL 7035	5U	221.4mm	95HP	483mm
30118-307		RAL 7035	8U	354.8mm	95HP	483mm
30118-309		RAL 7035	10U	443.7mm	95HP	483mm
30118-949		RAL 7021	2U	88.1mm	95HP	483mm
30118-952		RAL 7021	5U	221.4mm	95HP	483mm
30118-955		RAL 7021	8U	354.8mm	95HP	483mm
30118-957		RAL 7021	10U	443.7mm	95HP	483mm
30219-101	No		2U	88.1mm	95HP	483mm

Catalog Number	Treated Edges	Color Code	Rack Height	Height (H)	Rack Width	Width (W)
30219-110	No		5U	221.4mm	95HP	483mm
30219-138	No		8U	354.8mm	95HP	483mm
30219-144	No		10U	443.7mm	95HP	483mm
40304-075	Yes		2U	88.1mm	95HP	483mm
40304-078	Yes		5U	221.4mm	95HP	483mm
40304-081	Yes		8U	354.8mm	95HP	483mm
40304-083	Yes		10U	443.7mm	95HP	483mm


Table 3/3			
Catalog Number	Depth (D)	Package Quantity	Finish
30118-948	3mm	1	Powder Coated
30118-299	3mm	1	Powder Coated
30219-098	3mm	1	Anodized
40304-074	4mm	1	Anodized
30118-950	3mm	1	Powder Coated
30118-302	3mm	1	Powder Coated
30219-104	3mm	1	Anodized
40304-076	4mm	1	Anodized
30118-951	3mm	1	Powder Coated
30118-303	3mm	1	Powder Coated
30219-107	3mm	1	Anodized
40304-077	4mm	1	Anodized
30118-953	3mm	1	Powder Coated
30118-305	3mm	1	Powder Coated
30219-113	3mm	1	Anodized
40304-079	4mm	1	Anodized
30118-954	3mm	1	Powder Coated
30118-306	3mm	1	Powder Coated
30219-137	3mm	1	Anodized
40304-080	4mm	1	Anodized
30118-956	3mm	1	Powder Coated
30118-308	3mm	1	Powder Coated
30219-143	3mm	1	Anodized
40304-082	4mm	1	Anodized
30118-301	3mm	1	Powder Coated

Catalog Number	Depth (D)	Package Quantity	Finish
30118-304	3mm	1	Powder Coated
30118-307	3mm	1	Powder Coated
30118-309	3mm	1	Powder Coated
30118-949	3mm	1	Powder Coated
30118-952	3mm	1	Powder Coated
30118-955	3mm	1	Powder Coated
30118-957	3mm	1	Powder Coated
30219-101	3mm	1	Anodized
30219-110	3mm	1	Powder Coated
30219-138	3mm	1	Anodized
30219-144	3mm	1	Anodized
40304-075	4mm	1	Anodized
40304-078	4mm	1	Anodized
40304-081	4mm	1	Anodized
40304-083	4mm	1	Anodized

ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

DIAGRAMS

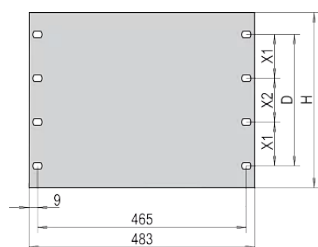

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER