


FRONT PANEL, SHIELDED, SIDE HINGED, 3 U, 84 HP, 2.5 MM, AL, FRONT ANODIZED, REAR CONDUCTIVE

CATALOG NUMBER

20848-611

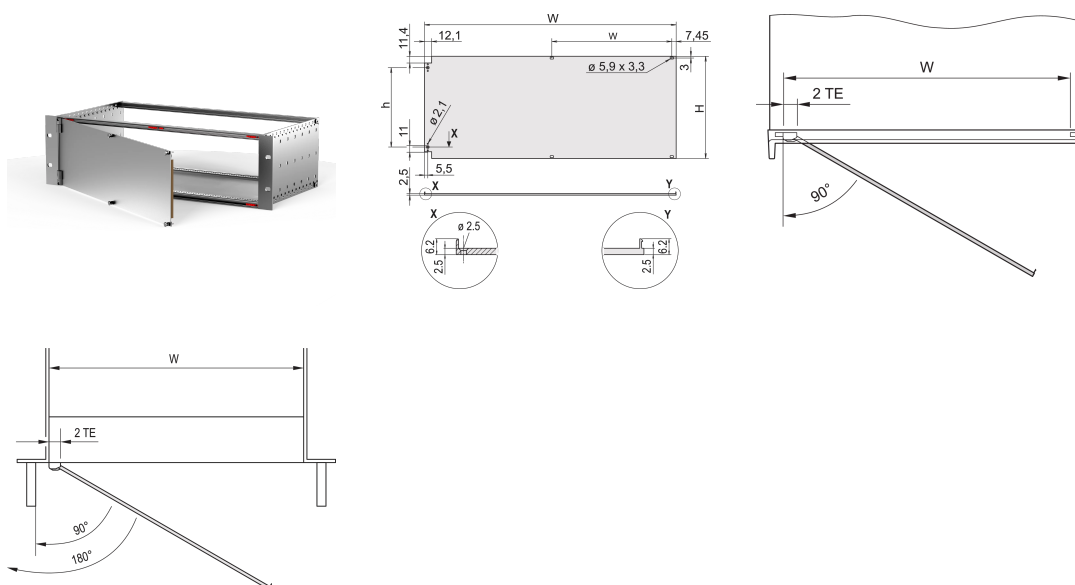

Front panel with textile EMC gasket, side hinged assembly.

CERTIFICATIONS



FEATURES

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails


Suitable for subracks and cases

Hinges can be fitted on left or right

PRODUCT ATTRIBUTES

Product Type: Front Panel
Type: Front Panel without Handle
Accessory Type: Front panel
Mounting: Hinged, Side
EMC Shielding: No (Retrofittable)
EMC Gasket Type: Textile
Material: Aluminum
Front Finish: Anodized
Rear Finish: Conductive
Treated Edges: No
Rack Height: 3U
Height (H): 128.4mm
Rack Width: 84HP
Width (W): 426.4mm
Depth (D): 2.5mm
Package Quantity: 1
Finish: Anodized; Passivated

DIAGRAMS

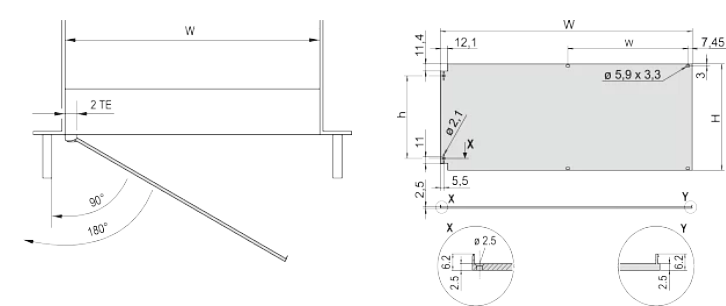

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations

+1.763.422.2661

Chat with us:

schroff.nvent.com

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

schroff.nvent.com

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER