


EUROPACPRO FRONT PANEL FOR 19" MODULE SUPPORT, 3 U, 84 HP, 2.5 MM, AL, FRONT ANODIZED, REAR CONDUCTIVE

CATALOG NUMBER

24563-096

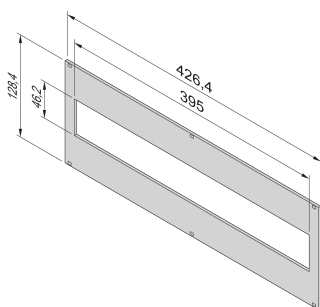

Front panel with cut-out in accordance with DIN 43880 (for power distribution modules).

CERTIFICATIONS



FEATURES

Front panel with cut-out conforming to DIN 43880 (for power distribution modules)

Height 3 U, width 84 HP

PRODUCT ATTRIBUTES

Product Type: Front Panel

Product Family: EuropacPRO

Accessory Type: Front panel

Mounting: Screw-on Front

Material: Aluminum

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Rack Height: 3U

Height: 128.4mm
Rack Width: 84HP
Width: 426.4mm
Depth: 2.5mm
Package Quantity: 1
Finish: Anodized; Passivated

ADDITIONAL PRODUCT DETAILS

2 Plastic cover strips are included in the form of delivery.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America All locations +1.763.422.2661 Chat with us: schroff.nvent.com	Europe Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: schroff.nvent.com	Asia Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: schroff.nvent.com	Middle East & India Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: schroff.nvent.com
---	---	---	---