


CPCI SYSTEM WITH PSB, 10 U, 14 SLOT

CATALOG NUMBER

24579-028

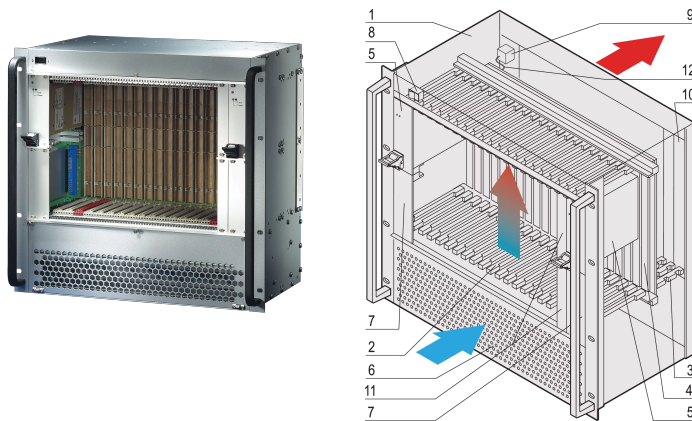

10 U CompactPCI System with PSB for fourteen 6 U Boards, fourteen RTM Boards and up to four 3U pluggable Power Supplies.

CERTIFICATIONS



FEATURES

System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11); Backplane, conforms to PICMG 2.16

System with vertical card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Backplane, PSB (package switched backplane), PICMG 2.16 16-slot, 6 U, 64 bit (2 fabric/switch slots, 14 node slots)

Heat dissipation by fan module, from front to rear

Two 19" CompactPCI power supplies, 300 W (3 U, 8 HP), prepared for installation of two additional 19" compatible PSUs

Prepared for system monitoring with a chassis monitoring module (CMM)

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 16

Type: 19" Rack Mount
Backplane Type: 6 U CompactPCI with PSB
Data Transfer: 64-bit PCI Bus; GbE
Power per Slot: 40W
Input Voltage AC: 100 – 240V
Airflow Direction: Front to Rear
Rack Height: 10U
Power Supply Type: (2) Pluggable AC PSU
Power Supply Included: Yes
Rear I/O: Yes
Complies With: PICMG 2.0 R3.0
Depth: 275mm
Height: 443.7mm
Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Modified systems available on request.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com