


CPCI SYSTEM FOR PLUGGABLE PSU, HORIZONTAL, 3 U, 6 SLOT

CATALOG NUMBER

24579-080

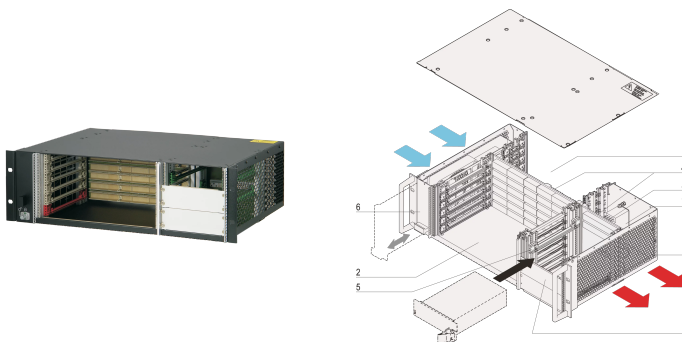

3 U CompactPCI System with horizontal Card Cage for six 6 U Boards, six RTM Boards and one CompactPCI 3 U Pluggable Power Supply. Option to assemble up to three pluggable Power Supplies.

CERTIFICATIONS



FEATURES

In accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; backplane in accordance with PICMG 2.0 rev. 3.0

System with horizontal card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Backplane (signal and power backplane in one unit) 6 slot, 6 U, 64 bit, System slot left, Power connector (2 x P 47)

Heat dissipation by hot-swap fan unit (airflow left to right)

Prepared for the assembly of a 19" CompactPCI power supply (3 U, 8 HP)

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 6

Type: 19" Rack Mount

Backplane Type: 6 U CompactPCI

| |
|--------------------------------------|
| Data Transfer: 64-bit PCI Bus |
| Power per Slot: 40W |
| Input Voltage AC: 100 – 240V |
| Airflow Direction: Left to Right |
| Rack Height: 3U |
| Power Supply Type: (1) Pluggable PSU |
| Power Supply Included: No |
| Rear I/O: Yes |
| Complies With: PICMG 2.0 R3.0 |
| Depth: 275mm |
| Height: 132.5mm |
| Width: 449mm |
| Package Quantity: 1 |

ADDITIONAL PRODUCT DETAILS

Modified systems available on request.

48 VDC version on request.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com