


HORIZONTAL RAIL, FRONT, TYPE H-LD, HEAVY, LONG LIP, FOR IEEE APPLICATION, 84 HP

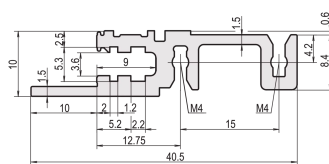




 
 


 


**CATALOG NUMBER**

**34560-384**



# Combinations of horizontal rails and side panels

$\Delta^H =$  can be combined.  $\Delta^V =$  combination not recommended

	AluSign® 4	AluSign® 5	AluSign® 6	AluSign® 8
AluSign® 4		-	+	+
AluSign® 5		+	sidekick 100 Double for Corner®	sidekick 100 Heavy Duty for Corner®
AluSign® 6		sidekick 100 Light	sidekick 100 Double	+
AluSign® 8		-	-	-
Decorated rail				
Side panel				

AluSign® 4 AluSign® 5 AluSign® 6 AluSign® 8

Decorated rail Side panel

AluSign® 4 AluSign® 5 AluSign® 6 AluSign® 8

The horizontal rail with a long lip enables the use of IEEE insertion / extraction handles.

## CERTIFICATIONS



## FEATURES

For plug-in units with IEEE handle

Long lip (H-LD)

## Installation at top and bottom

For CPCI and VME64x systems

Aluminum extrusion, anodized finish, conductive contact surface

## PRODUCT ATTRIBUTES

Product Type: Horizontal Rail

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Type: Heavy, LD

Rack Width: 84HP

Length: 431.8mm
Package Quantity: 1
Finish: Anodized
Material: Aluminum

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

<b>North America</b> All locations +1.763.422.2661 Chat with us: <a href="http://schroff.nvent.com">schroff.nvent.com</a>	<b>Europe</b> Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: <a href="http://schroff.nvent.com">schroff.nvent.com</a>	<b>Asia</b> Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: <a href="http://schroff.nvent.com">schroff.nvent.com</a>	<b>Middle East &amp; India</b> Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: <a href="http://schroff.nvent.com">schroff.nvent.com</a>
---	---	---	---