


TELESCOPIC SLIDE SLIM LINE, LENGTH 559 MM

CATALOG NUMBER

60110-440

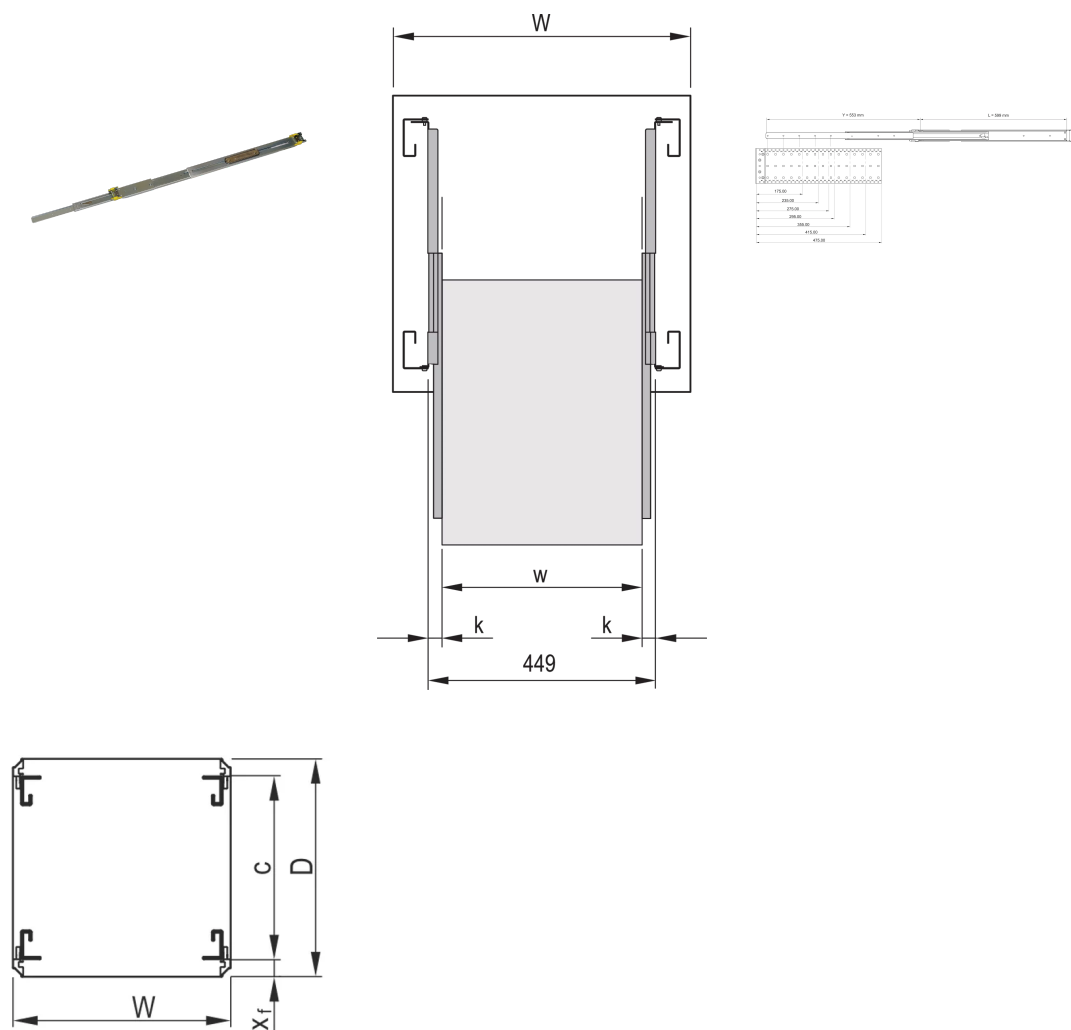

Narrow Telescopic Slide for Subracks with > 100 % extension.

CERTIFICATIONS



FEATURES

Suitable for 84 HP width subracks (type F, type H, type L)
Locks at full extension
Hinged
Extension length > 100 %
Rail width 7.5 mm
Maximum clear width of extension/drawer w = 84 HP (435 mm)

PRODUCT ATTRIBUTES

Product Type: Telescopic Slide
Type: Narrow
Length: 559mm
Static Load: 15kgf
Package Quantity: 2
Finish: Zinc Plated
Material: Steel

ADDITIONAL PRODUCT DETAILS

To mount on 19" plane please order assembly kit separately.

Telescopic slight can only be assembled to a subrack without an assembled rear angle or a modified rear angle (with special cutout).

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations

+1.763.422.2661

Chat with us:

schroff.nvent.com

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

schroff.nvent.com

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER