


## GUIDE RAIL STANDARD TYPE, PC, 220 MM, 2 MM GROOVE WIDTH, RED

### CATALOG NUMBER

**64568-002**

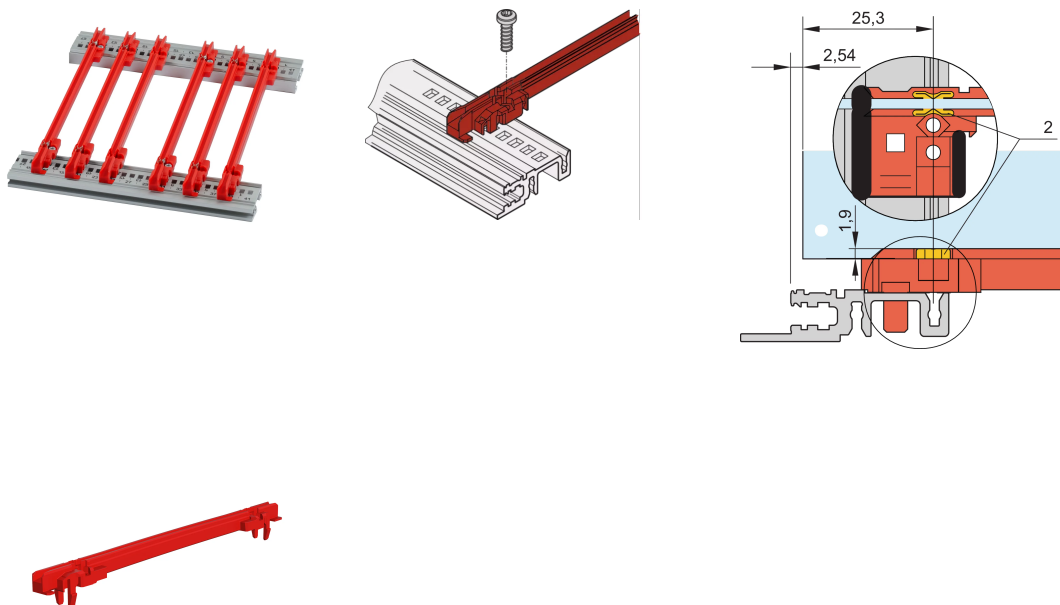

New generation of accessory type guide rails for PCBs or plug-in units. Forms a reliable interface between the subrack mechanics and the sub-assemblies.

### CERTIFICATIONS



### FEATURES

NEW generation Standard type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to a optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates
Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements
Optional ESD clip for an conductive contact between PCB and horizontal rail available
Storage temperature: from -40 °C ... 130 °C

PRODUCT ATTRIBUTES

Product Type: Guide Rail
Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Type: Standard
Works With: Subracks; Cases; 19" Chassis; Systems
Board Depth: 220mm
Groove Width: 2
Material: Fiber-Reinforced Plastic
Color: Red
Complies With: EN 45545-2
Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab Emirates
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	+971.4.378.1700
Chat with us:	Betschdorf, France	Qingdao, China	Bangalore, India
<a href="http://schroff.nvent.com">schroff.nvent.com</a>	+33.3.88.90.64.90	+86.532.8771.6101	+91.80.6715.2001
	Warsaw, Poland	Singapore	Istanbul, Turkey
	+48.22.209.98.35	+65.6768.5800	+90.216.250.7374
	Assago, Italy	Shin-Yokohama, Japan	Chat with us:
	+39.02.932.7141	+81.45.476.0271	<a href="http://schroff.nvent.com">schroff.nvent.com</a>
	Chat with us:	Chat with us:	
	<a href="http://schroff.nvent.com">schroff.nvent.com</a>	<a href="http://schroff.nvent.com">schroff.nvent.com</a>	