


FRONT PANEL EMC TEXTILE SHIELDING KIT, -40 UP TO +70°C

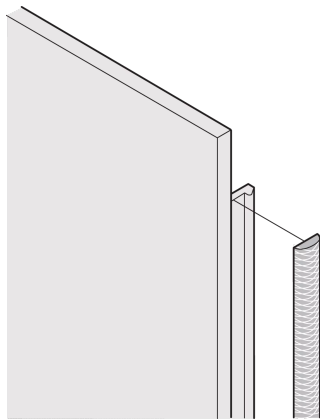

The textile EMC gaskets are inserted into a slot on the right hand side of the U-shaped front panels. The gaskets are glued to the front panel.

CERTIFICATIONS



FEATURES

Textile EMC gasket is affixed laterally on the front panel or in the groove of the right-hand profile as appropriate.

Profile seal is bonded onto the contact surface of the 19" bracket or of the rear angle and sets up the conductive connection to the U-shaped front panels

Temperature range -40 °C ... +70 °C

SPECIFICATIONS

Table 1/2

Catalog Number	Rack Height	Material	Package Quantity	Height (H)	Depth (D)	Flammability Rating
21101-853	3U	Thermoplastic Elastomer	10	97mm	1.62mm	UL® 94V-0
21101-855	6U	Thermoplastic Elastomer	10	232mm	1.62mm	UL® 94V-0
21101-857	2U	Thermoplastic Elastomer	10	52mm	1.62mm	UL® 94V-0


Catalog Number	Rack Height	Material	Package Quantity	Height (H)	Depth (D)	Flammability Rating
21101-859	9U	Thermoplastic Elastomer	10	365.5mm	1.62mm	UL® 94V-0
21101-854	3U	Thermoplastic Elastomer	100	97mm	1.62mm	UL® 94V-0
21101-856	6U	Thermoplastic Elastomer	100	232mm	1.62mm	UL® 94V-0
21101-858	4U	Thermoplastic Elastomer	10			
21101-978	5U	Thermoplastic Elastomer	10			
21101-904	9U	Thermoplastic Elastomer	100			

Table 2/2	
Catalog Number	Width (W)
21101-853	3.8mm
21101-855	3.8mm
21101-857	3.8mm
21101-859	3.8mm
21101-854	3.8mm
21101-856	3.8mm
21101-858	
21101-978	
21101-904	

ADDITIONAL PRODUCT DETAILS

EMC gaskets (textile) are required for shielding the front panels.

DIAGRAMS

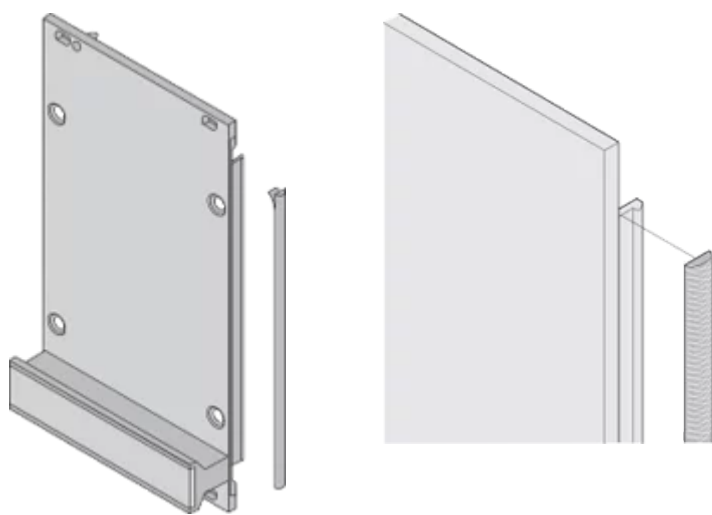

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER