


FRONT PANEL, U-PROFILE, REFROFIT SHIELDING

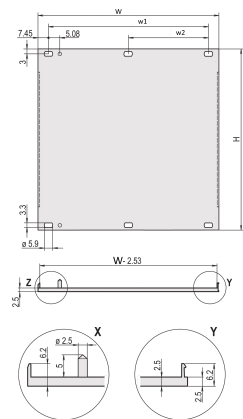

U-profile front panel for textile EMC gasket.

CERTIFICATIONS



FEATURES

U-profile, front panel, Al, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

SPECIFICATIONS

Accessory Type: Front panel

Table 1/3

Catalog Number	Type	Mounting	EMC Shielding	EMC Gasket Type	Material	Front Finish
20848-260	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-261	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-027	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized

Catalog Number	Type	Mounting	EMC Shielding	EMC Gasket Type	Material	Front Finish
20848-047	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-068	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-097	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-269	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-270	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-271	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-189	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-013	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-015	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-020	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-106	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-108	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-113	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-120	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-139	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-160	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-206	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-262	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-268	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-280	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized

Catalog Number	Type	Mounting	EMC Shielding	EMC Gasket Type	Material	Front Finish
20848-647	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-648	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-649	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
20848-650	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-354	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-355	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-356	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-357	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-358	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-359	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-378	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-379	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-380	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-381	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-382	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-383	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-384	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-385	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-386	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30848-387	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized

Catalog Number	Type	Mounting	EMC Shielding	EMC Gasket Type	Material	Front Finish
30849-001	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30849-002	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30849-004	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized
30849-005	Front Panel without Handle	Screw-on Front	No (Retrofittable)	Textile	Aluminum	Anodized

Table 2/3						
Catalog Number	Rear Finish	Treated Edges	Rack Height	Height (H)	Depth (D)	Rack Width
20848-260	Conductive	No	2U	84mm	2.5mm	42HP
20848-261	Conductive	No	2U	84mm	2.5mm	63HP
20848-027	Conductive	No	3U	128.4mm	2.5mm	28HP
20848-047	Conductive	No	3U	128.4mm	2.5mm	42HP
20848-068	Conductive	No	3U	128.4mm	2.5mm	63HP
20848-097	Conductive	No	3U	128.4mm	2.5mm	84HP
20848-269	Conductive	No	4U	172.9mm	2.5mm	42HP
20848-270	Conductive	No	4U	172.9mm	2.5mm	42HP
20848-271	Conductive	No	4U	172.9mm	2.5mm	84HP
20848-189	Conductive	No	6U	261.8mm	2.5mm	84HP
20848-013	Conductive	No	3U	128.4mm	2.5mm	14HP
20848-015	Conductive	No	3U	128.4mm	2.5mm	16HP
20848-020	Conductive	No	3U	128.4mm	2.5mm	21HP
20848-106	Conductive	No	6U	261.8mm	2.5mm	14HP
20848-108	Conductive	No	6U	261.8mm	2.5mm	16HP
20848-113	Conductive	No	6U	261.8mm	2.5mm	21HP
20848-120	Conductive	No	6U	261.8mm	2.5mm	28HP
20848-139	Conductive	No	6U	261.8mm	2.5mm	42HP
20848-160	Conductive	No	6U	261.8mm	2.5mm	63HP
20848-206	Conductive	No	2U	84mm	2.5mm	28HP
20848-262	Conductive	No	2U	84mm	2.5mm	84HP
20848-268	Conductive	No	4U	172.9mm	2.5mm	28HP
20848-280	Conductive	No	9U	395.1mm	2.5mm	84HP
20848-647	Conductive	No	5U	217.4mm	2.5mm	28HP

Catalog Number	Rear Finish	Treated Edges	Rack Height	Height (H)	Depth (D)	Rack Width
20848-648	Conductive	No	5U	217.4mm	2.5mm	42HP
20848-649	Conductive	No	5U	217.4mm	2.5mm	63HP
20848-650	Conductive	No	5U	217.4mm	2.5mm	84HP
30848-354	Conductive	No	3U	128.4mm	2.5mm	4HP
30848-355	Conductive	No	6U	261.8mm	2.5mm	4HP
30848-356	Conductive	No	3U	128.4mm	2.5mm	8HP
30848-357	Conductive	No	6U	261.8mm	2.5mm	8HP
30848-358	Conductive	No	3U	128.4mm	2.5mm	12HP
30848-359	Conductive	No	6U	261.8mm	2.5mm	12HP
30848-378	Conductive	No	3U	128.4mm	2.5mm	5HP
30848-379	Conductive	No	6U	261.8mm	2.5mm	5HP
30848-380	Conductive	No	3U	128.4mm	2.5mm	6HP
30848-381	Conductive	No	6U	261.8mm	2.5mm	6HP
30848-382	Conductive	No	3U	128.4mm	2.5mm	7HP
30848-383	Conductive	No	6U	261.8mm	2.5mm	7HP
30848-384	Conductive	No	3U	128.4mm	2.5mm	9HP
30848-385	Conductive	No	3U	261.8mm	2.5mm	9HP
30848-386	Conductive	No	3U	128.4mm	2.5mm	10HP
30848-387	Conductive	No	6U	261.8mm	2.5mm	10HP
30849-001	Conductive	No	3U	128.4mm	2.5mm	2HP
30849-002	Conductive	No	6U	261.8mm	2.5mm	2HP
30849-004	Conductive	No	3U	128.4mm	2.5mm	3HP
30849-005	Conductive	No	6U	261.8mm	2.5mm	3HP

Table 3/3					
Catalog Number	Width (W)	Complies With	Package Quantity	Finish	Certifications
20848-260	213mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	
20848-261	319.7mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	
20848-027	141.9mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-047	213mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-068	319.7mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS

CatalogNumber	Width (W)	Complies With	Package Quantity	Finish	Certifications
20848-097	426.4mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-269	213mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-270	213mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-271	426.4mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-189	426.4mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-013	70.8mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-015	80.9mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-020	106.3mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-106	70.8mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-108	80.9mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-113	106.3mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-120	141.9mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-139	213mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-160	319.7mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-206	141.9mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	
20848-262	426.4mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-268	141.9mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-280	426.4mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
20848-647	141.9mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	
20848-648	213mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	

CatalogNumber	Width (W)	Complies With	Package Quantity	Finish	Certifications
20848-649	319.7mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	
20848-650	426.4mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	
30848-354	20mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-355	20mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-356	40.3mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-357	40.3mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-358	60.6mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-359	60.6mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-378	25mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-379	25mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-380	30.1mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-381	30.1mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-382	35.2mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-383	35.2mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-384	45.38mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	
30848-385	45.38mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	
30848-386	50.5mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30848-387	50.5mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30849-001	9.8mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS
30849-002	9.8mm	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated	RoHS

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER