


MOUNTING PLATE FOR 19" CASE AND SUBRACK

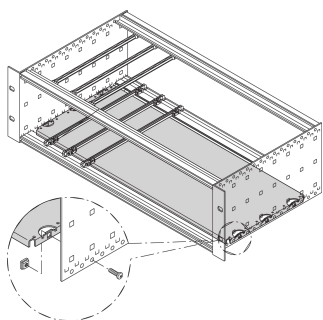

Mounting plate for heavy components or proprietary electronic assemblies. Suitable for RatiopacPRO/-AIR, CompacPRO and EuropacPRO.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

CERTIFICATIONS



FEATURES

For assembly of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

Mounting plate, partial width: The partial width mounting plate fixed to the side panel by means of an assembly strip

The chassis plate can't be combined with EMC top- / bottom covers

SPECIFICATIONS

Table 1/1

Catalog Number	Rack Width	Width	Depth	Material	Package Quantity	Certifications
34562-750	42HP	217.99mm	172.5mm	Aluminum	1	RoHS
34562-746	42HP	217.99mm	112.5mm	Aluminum	1	RoHS
34562-754	42HP	217.99mm	232.5mm	Aluminum	1	RoHS
34562-758	42HP	217.99mm	292.2mm	Aluminum	1	RoHS
34562-752	84HP	431.35mm	172.5mm	Aluminum	1	RoHS
34562-748	84HP	324.67mm	112.5mm	Aluminum	1	RoHS

Catalog Number	Rack Width	Width	Depth	Material	Package Quantity	Certifications
34562-756	84HP	431.35mm	232.5mm	Aluminum	1	RoHS
34562-760	84HP	431.35mm	292.5mm	Aluminum	1	RoHS
34562-749	28HP	146.88mm	172.5mm	Aluminum	1	RoHS
34562-745	28HP	146.88mm	112.5mm	Aluminum	1	RoHS
34562-753	28HP	146.88mm	232.5mm	Aluminum	1	RoHS
34562-751	63HP	324.67mm	172.5mm	Aluminum	1	RoHS
34562-747	63HP	324.67mm	112.5mm	Aluminum	1	RoHS
34562-755	63HP	324.67mm	232.5mm	Aluminum	1	RoHS
34562-759	63HP	324.67mm	292.2mm	Aluminum	1	RoHS
34562-870	84HP	431.35mm	352.5mm	Aluminum	1	
34562-871	84HP	431.35mm	412.5mm	Aluminum	1	
34562-757	28HP	146.88mm	292.2mm	Aluminum	1	RoHS

ADDITIONAL PRODUCT DETAILS

Please order assembly kit for mounting plate separately.

Other versions on request.

Fixing strips required for partial width, please order separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction,

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER