


SOCKET STRIP, UTE

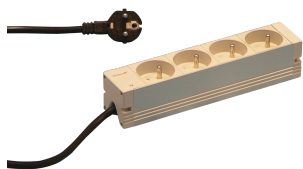

Modular, compact PDU with many function elements. Using a 1 U by 1 U aluminum chassis the PDU can easily be integrated in a rack with UTE outlets.

CERTIFICATIONS



FEATURES

230 V, 16 A

In accordance with NFC 61-303

Socket strip with UTE sockets

Mounting height 1 U

Horizontal or vertical mounting

Connecting cable 2 m, with SCHUKO/UTE plug

Socket strips can be rotated through all four directions (in 90° increments) during installation

SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Socket Type	Socket Quantity	Switched Outlets	Color	Voltage AC
60110-220	Socket Strip	UTE	4	No	Grey	230V
60110-221	Socket Strip	UTE	9	No	Grey	230V
60110-222	Socket Strip	UTE	12	No	Grey	230V

Catalog Number	ProductType	Socket Type	Socket Quantity	Switched Outlets	Color	Voltage AC
60110-223	Socket Strip	UTE	15	No	Grey	230V
60110-224	Socket Strip	UTE	19	No	Grey	230V
60110-225	Socket Strip	UTE	8	Yes	Grey	230V
60110-226	Socket Strip	UTE	12	Yes	Grey	230V
60110-227	Socket Strip	UTE	8	No	Grey	230V
60110-228	Socket Strip	UTE	6	No	Grey	230V
60110-229	Socket Strip	UTE	7	No	Grey	230V
60110-230	Socket Strip	UTE	6	No	Grey	230V
60110-231	Socket Strip	UTE	6	No	Grey	230V
60110-267	Socket Strip	UTE	6	No	Grey	230V

Table 2/2						
Catalog Number	Function	Length	Depth	Material	Finish	Package Quantity
60110-220		210mm	44mm	Aluminum, Polyamide	Anodized	1
60110-221		438.5mm	44mm	Aluminum, Polyamide	Anodized	1
60110-222		947.5mm	44mm	Aluminum, Polyamide	Anodized	1
60110-223		1202mm	44mm	Aluminum, Polyamide	Anodized	1
60110-224		1753mm	44mm	Aluminum, Polyamide	Anodized	1
60110-225		438.5mm	44mm	Aluminum, Polyamide	Anodized	1
60110-226		947.5mm	44mm	Aluminum, Polyamide	Anodized	1
60110-227	Transient Protection	438.5mm	44mm	Aluminum, Polyamide	Anodized	1
60110-228	Overcurrent Protection	438.5mm	75mm	Aluminum, Polyamide	Anodized	1
60110-229	Mains Suppression Filter	438.5mm	44mm	Aluminum, Polyamide	Anodized	1
60110-230	Fault Current Protection	438.5mm	88mm	Aluminum, Polyamide	Anodized	1

Catalog Number	Function	Length	Depth	Material	Finish	Package Quantity
60110-231	Fault Current Protection, Overcurrent Protection	438.5mm	88mm	Aluminum, Polyamide	Anodized	1
60110-267	Transient Protection, Mains Suppression Filter	438.5mm	44mm	Aluminum, Polyamide	Anodized	1

ADDITIONAL PRODUCT DETAILS

Please order bracket for vertical mounting separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER