

## BRANCH LINE RESTRAINT STRUCTURE ATTACHMENT TO STEEL



### CERTIFICATIONS



### FEATURES

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to steel members with self-drilling/tapping screw

### SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Flange Thickness (FT)	Length (L)	Rod Size (RS)
CSBBRS1MEG	402239	Steel	Electrogalvanized	2.7 – 12.7mm	40.4mm	10, 12

Table 2/2

Catalog Number	Article Number	Screw Diameter (Sc)	Height (H)	Screw Length (L)	Width (W)
CSBBRS1MEG	402239	2.7mm	28.2mm	32mm	26.9mm


## ADDITIONAL PRODUCT DETAILS

---

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

## DIAGRAMS

---

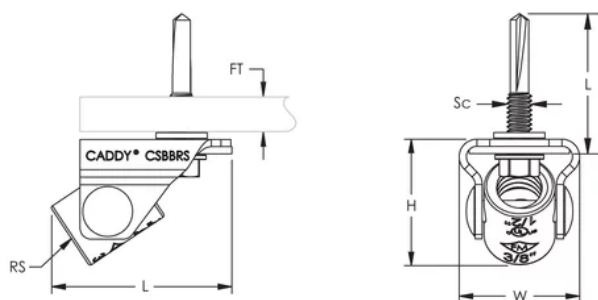

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**