

## BRANCH LINE RESTRAINT STRUCTURE ATTACHMENT TO THREADED HOLE



### CERTIFICATIONS



### FEATURES

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to concrete anchors or structural attachments with female threads

Can be used for bolting through steel

### SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Length (L)	Rod Size (RS)	Screw Diameter (Sc)
CSBBRS3MEG	402241	Steel	Electrogalvanized	40.4mm	10, 12	10

Table 2/2

Catalog Number	Article Number	Height (H)	Screw Length (L)	Width (W)
CSBBRS3MEG	402241	28.2mm	19mm	26.9mm


## ADDITIONAL PRODUCT DETAILS

---

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

## DIAGRAMS

---

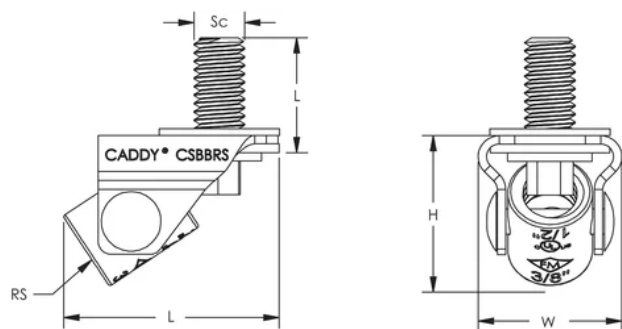

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



[nVent.com](http://nVent.com)

**TRACER**

Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN RAYCHEM SCHROFF**