



## 2HPS TWO HOLE PIPE STRAP



### FEATURES

Light duty support of pipe

Attaches directly to the face of a horizontal or vertical structural member

### SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel

Table 1/2


Catalog Number	Article Number	Pipe Size	NB/DN	Outer Diameter (OD)	Hole Size (HS)	Width (W)
008017EG	400678	3/8"	10	17.2 mm	7 mm	20 mm
008021EG	400679	1/2"	15	21.3 mm	7 mm	20 mm
008027EG	400680	3/4"	20	26.9 mm	7 mm	20 mm
008034EG	400681	1"	25	33.7 mm	7 mm	20 mm
008042EG	400682	1 1/4"	32	42.4 mm	7 mm	20 mm
008048EG	400683	1 1/2"	40	48.3 mm	7 mm	20 mm
008060EG	400684	2"	50	60.3 mm	7 mm	20 mm

Table 2/2

Catalog Number	Article Number	Thickness (T)
008017EG	400678	1 mm

Catalog Number	Article Number	Thickness (T)
008021EG	400679	1 mm
008027EG	400680	1 mm
008034EG	400681	1 mm
008042EG	400682	1 mm
008048EG	400683	1 mm
008060EG	400684	1 mm

### DIAGRAMS

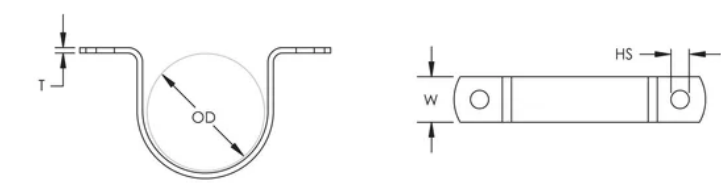

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**