


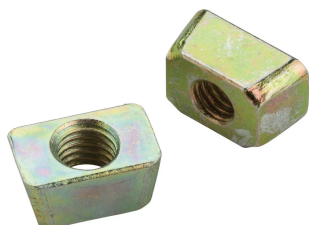

HW WEDGE NUT FOR DOVETAIL DECK



FEATURES

Trapeze nut for hanging threaded rod from steel ceilings

Installs easily

Fits several composite floor decking profiles

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

| Catalog Number | Article Number | Rod Size (RS) | Angle (a) | A | B | C |
|----------------|----------------|---------------|-----------|-------|--------|--------|
| PHWC6 | 196240 | 6 | 25 ° | 18 mm | 9.5 mm | 9.5 mm |
| PHWC8 | 196250 | 8 | 25 ° | 18 mm | 9.5 mm | 9.5 mm |
| HW10 | 187290 | 10 | 15 ° | 25 mm | 12 mm | 12 mm |
| HW6 | 187270 | 6 | 15 ° | 25 mm | 12 mm | 12 mm |
| HW8 | 187280 | 8 | 15 ° | 25 mm | 12 mm | 12 mm |
| HW12 | 187300 | 12 | 15 ° | 25 mm | 16 mm | 16 mm |


Table 2/2

| Catalog Number | Article Number | Static Load (F) |
|----------------|----------------|-----------------|
| PHWC6 | 196240 | 1200N |
| PHWC8 | 196250 | 1700N |

| Catalog Number | Article Number | Static Load (F) |
|----------------|----------------|-----------------|
| HW10 | 187290 | 2100N |
| HW6 | 187270 | 1200N |
| HW8 | 187280 | 1700N |
| HW12 | 187300 | 2100N |

| Metal Decking Compatibility for Wedge Nuts | | | | | | | | |
|--|---------------|-----|-----|-----|------|------|-------|-------|
| Part Number | | HW4 | HW6 | HW8 | HW10 | HW12 | PHWC6 | PHWC8 |
| TATA | Comflor 51+ | X | X | X | X | X | | |
| | Comflor 60/75 | | | | | | X | X |
| | Comflor 80/95 | | | | | | X | X |
| | Ribdeck 80 | | | | | | X | X |
| SMD | R51+ | X | X | X | X | X | | |
| KINGSPAN | Multideck 50 | X | X | X | X | X | | |
| CMF | Metfloor 55 | X | X | X | X | X | | |

DIAGRAMS

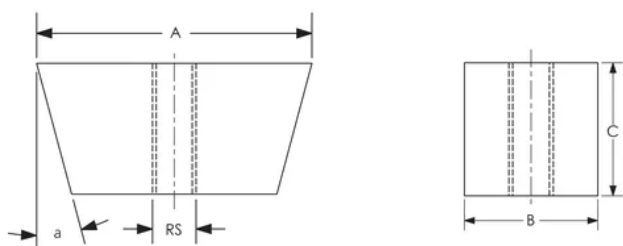

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER