




# IMPROVED NVENT CADDY CAT HP J-HOOK MOD CLIP WITH BC BEAM CLAMP, SWIVEL

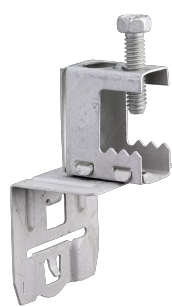

The Improved nVent CADDY Cat HP Mod Clip J-Hook with BC Swivel Beam Clamp offers both easy beam flange installation and 360-degree rotation for versatile cable routing. By eliminating the need for screws, rivets or special tools during assembly, installation time and cost is reduced. A simple clip onto nVent CADDY Cat HP components ensures a secure hold—ultimately enhancing rigidity and stability while minimizing inventory impact and providing flexibility on the job site.

## CERTIFICATIONS



## FEATURES


Rotates 360 degrees to support various directional runs of cable

Works with nVent J-Hook Versa-Mount technology from nVent CADDY

## SPECIFICATIONS

Table 1/1					
Catalog Number	Article Number	Finish	Material	Flange Thickness (FT)	Static Load (F)
CATHPMBCB	186079	Electrogalvanized, nVent CADDY Armour	Steel, Spring Steel	16 mm Max	267N

DIAGRAMS

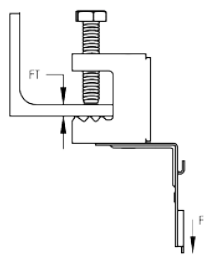

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

<b>North America</b> +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	<b>Europe</b> Netherlands: +31 800-0200135 France: +33 800 901 793	<b>Europe</b> Germany: 800 1890272 Other Countries: +31 13 5835404	<b>APAC</b> Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--