



NVENT CADDY MACROFIX PLUS NON-INSULATED



CERTIFICATIONS



FEATURES

Increased opening angle easily accommodates all standard-sized pipes

Quick locking system prevents the hanger from accidentally opening when pipe is moved or adjusted

Quick locking system easily closes with one hand

Thread impression retains quick locking captive screw and prevents it from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	Outer Diameter (OD)	Rod Size (RS)	NB/DN	Pipe Size	Pipe Size Range
MFZ019	586801	15 - 19 mm	8, 10	10	3/8"	0.375 in
MFZ023	586802	19 - 23 mm	8, 10	15	1/2"	0.5 in
MFZ029	586803	23 - 29 mm	8, 10	20	3/4"	0.75 in
MFZ035	586804	29 - 35 mm	8, 10	25	1"	1 in
MFZ041	586805	35 - 41 mm	8, 10			
MFZ048	586806	41 - 48 mm	8, 10	32	1 1/4"	1.25 in min
MFZ055	586807	49 - 55 mm	8, 10	40	1 1/2"	1.5 in
MFZ062	586808	54 - 62 mm	8, 10	50	2"	2 in min
MFZ072	586809	62 - 72 mm	8, 10			
MFZ083	586810	73 - 83 mm	8, 10	65	2 1/2"	2.5 in
MFZ093	586811	83 - 93 mm	8, 10	80	3"	3 in
MFZ103	586812	93 - 103 mm	8, 10	90	3 1/2"	3.5 in
MFZ113	586813	103 - 113 mm	8, 10			
MFZ123	586814	113 - 123 mm	8, 10	100	4"	4 in
MFZ133	586815	123 - 133 mm	8, 10			
MFZ143	586816	133 - 143 mm	8, 10	125	5"	5 in
MFZ153	586817	143 - 153 mm	8, 10			
MFZ165	586818	155 - 165 mm	8, 10			
MFZ175	586819	165 - 175 mm	8, 10	150	6"	6 in
MFZ205	586820	195 - 205 mm	8, 10			
MFZ220	586821	210 - 220 mm	8, 10	200	8"	8 in

Table 2/2

Catalog Number	Article Number	Width (W)	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load (F)
MFZ019	586801	20 mm	1 mm	6	27mm	1000N
MFZ023	586802	20 mm	1 mm	6	27mm	1000N
MFZ029	586803	20 mm	1 mm	6	32mm	1000N
MFZ035	586804	20 mm	1 mm	6	32mm	1000N
MFZ041	586805	20 mm	1 mm	6	32mm	1000N
MFZ048	586806	20 mm	1 mm	6	32mm	1000N
MFZ055	586807	21 mm	1.25 mm	6	32mm	1500N
MFZ062	586808	21 mm	1.25 mm	6	32mm	1500N

Catalog Number	Article Number	Width (W)	Thickness(T)	Screw Diameter (Sc)	ScrewLength (L)	Static Load (F)
MFZ072	586809	21 mm	1.25 mm	6	37mm	1500N
MFZ083	586810	23 mm	1.5 mm	6	37mm	2000N
MFZ093	586811	23 mm	1.5 mm	6	37mm	2000N
MFZ103	586812	23 mm	1.75 mm	6	37mm	2500N
MFZ113	586813	23 mm	1.75 mm	6	37mm	2500N
MFZ123	586814	23 mm	1.75 mm	6	37mm	2500N
MFZ133	586815	23 mm	2 mm	6	40mm	3000N
MFZ143	586816	23 mm	2 mm	6	40mm	3000N
MFZ153	586817	25 mm	2 mm	6	40mm	3200N
MFZ165	586818	25 mm	2 mm	6	40mm	3200N
MFZ175	586819	25 mm	2 mm	6	40mm	3200N
MFZ205	586820	27 mm	2.25 mm	6	40mm	3600N
MFZ220	586821	27 mm	2.25 mm	6	40mm	3600N

DIAGRAMS

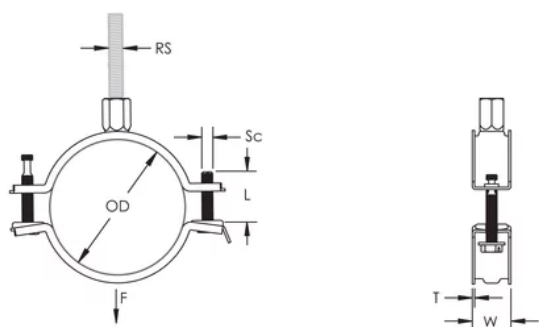

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER