


## FOUR POLE DISTRIBUTION BLOCK WITH THREADED BARS, 400 A

### CATALOG NUMBER

**TR-400A**

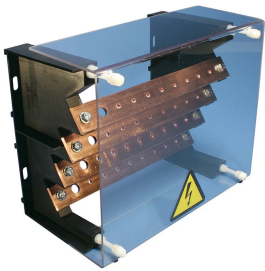

### CERTIFICATIONS



### FEATURES

- Easily fixes onto DIN rail or mounts with screws
- Bolts included for output connections
- Transparent protection cover
- Easy accessibility for wiring
- Ready to use out of the box, saving installation time and labor
- RoHS compliant

### PRODUCT ATTRIBUTES

- Article Number: 562010
- Material: Copper; Glass Fibre Reinforced Polyamide; Plexiglass
- Max Working Voltage, IEC (Ui): 1000
- Peak Short Circuit Current (I<sub>pk</sub>): 34kA
- Short Term Withstand Current (I<sub>cw</sub>) 1s: 28kA

Line Side Number of Connections: 1

Load Side Number of Connections: 8

Hole Size (HS): 10mm

Thread Size (TS): M6

Depth (D): 140mm

Height (H): 240mm

Width (W): 300mm

Unit Weight: 2.83kg

Flammability Rating: UL® 94V-0

Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)


## ADDITIONAL PRODUCT DETAILS

---

Line side and load side number of connections are per pole.

## DIAGRAMS

---

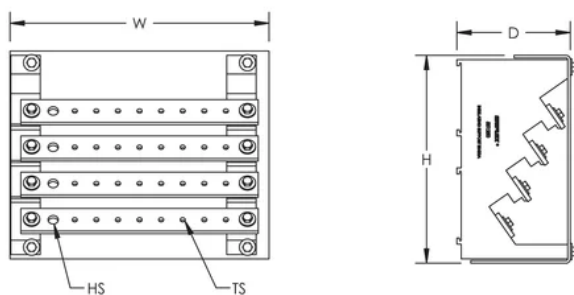

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**