


MS PDU, 2U, 60A(48A)NA/60A INT, 380-415V, 3P WYE, 9 CB, (9)C13, (9)4-IN-1

CATALOG NUMBER

EN2954

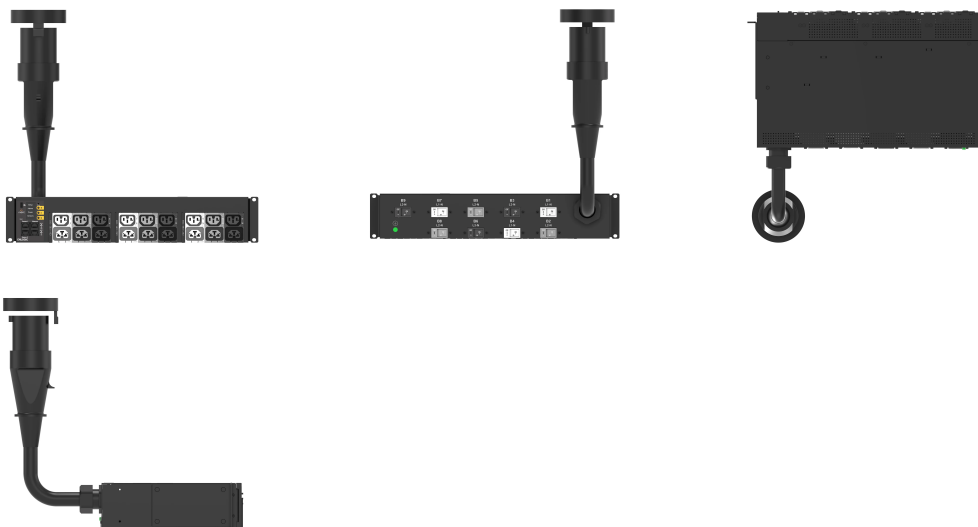

The Advantage Series Input Metered, Outlet Switched PDU family offers energy metering with advanced power and environmental monitoring options and remote outlet on/off switching. Comprehensive monitoring at both the input phase and circuit breaker levels offers advanced alerts of potential overloads. Billing-grade metering provides accurate power consumption data for energy use optimization. The hot-swappable network management controller features Gigabit and redundant ethernet communication with advanced support for external environmental sensors and rack security access solutions.

PRODUCT ATTRIBUTES

Socket Type: (9) C13/C15; (9) C13/C15/C19/C21

Color: Black

Switched Outlets: Yes

Circuit Breaker: 20 A

Circuit Breaker Quantity: 9

Input Voltage: 380-415 VAC, 3 PH

Nominal Voltage: 415V

Number of Poles: 1

Output Voltage: 208 – 230VAC

Plug Type: IEC 60309 560P6 (IP44)

Rack Units: 2U
Removable Input Cable: No
Product Type: Socket Strip
Product Family: Enlogic
Type: Intelligent PDU
Finish: Powder Coated
Material: Steel
Height: 87mm
Width: 444mm
Depth: 269mm
Weight: 9kg
Package Quantity: 1
Length: 87mm
Input Cable Length: 1.8m

ADDITIONAL PRODUCT DETAILS

87 mm L x 444 mm W x 269 mm D, (269 mm D at CB)

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.