

# AIR TERMINAL BASE, HORIZONTAL MOUNT, IMPERIAL THREAD



## CERTIFICATIONS



## FEATURES


Can be fastened mechanically or bonded using hot pitch, roofing compound or commercial adhesive on built-up roof surfaces or other location where holes cannot be made

Positive single bolt tension for multi-directional cable clamping

## SPECIFICATIONS

Table 1/1					
Catalog Number	Conductor Size, UL	Thread Size (TS)	Height (H)	Width (W)	Unit Weight
LPA30912	Class 1 - Class 2 (4/0 Max)	1/2" UNC	20.64 mm	101.600 mm	0.141 kg

## DIAGRAMS

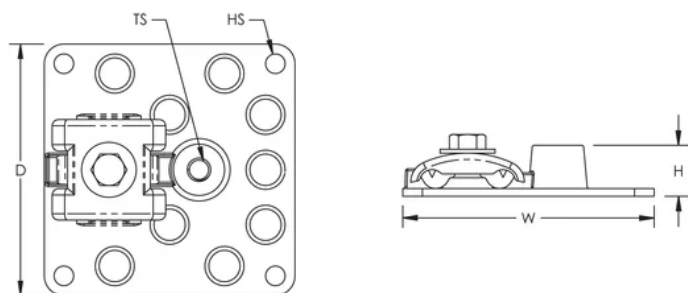

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**