


NOVASTAR FRAME, SLIM-LINE

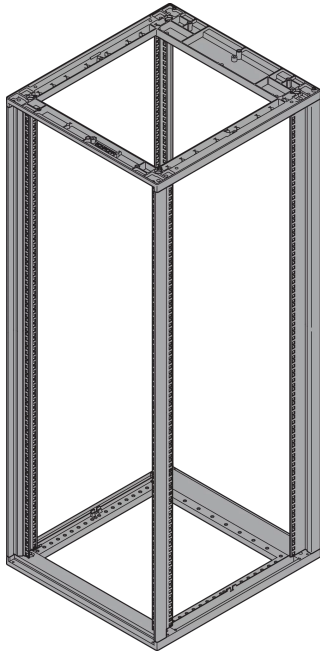

Aesthetic aluminum die-cast frame with 200kg static load capacity. Aluminum extruded 19" upright bolted onto the frames.

CERTIFICATIONS



FEATURES

Static load-carrying capacity 200 kg

19" plane - 33 mm at front, 60 mm at rear

Al profile, RAL 7021, incl. grounding

SPECIFICATIONS

Table 1/2

Catalog Number	Frame Material	Height	Product Type	Product Family	Type	Rack Height
28230-001	Aluminum	323 mm	Cabinet/Rack Frame	Novastar	Slim-Line	6 U

Catalog Number	Frame Material	Height	ProductType	Product Family	Type	Rack Height
28230-060	Aluminum	323 mm	Cabinet/Rack Frame	Novastar	Slim-Line	6 U
28230-004	Aluminum	456 mm	Cabinet/Rack Frame	Novastar	Slim-Line	9 U
28230-063	Aluminum	456 mm	Cabinet/Rack Frame	Novastar	Slim-Line	9 U
28230-007	Aluminum	589 mm	Cabinet/Rack Frame	Novastar	Slim-Line	12 U
28230-054	Aluminum	589 mm	Cabinet/Rack Frame	Novastar	Slim-Line	12 U
28230-055	Aluminum	589 mm	Cabinet/Rack Frame	Novastar	Slim-Line	12 U
28230-066	Aluminum	589 mm	Cabinet/Rack Frame	Novastar	Slim-Line	12 U
28230-126	Aluminum	589 mm	Cabinet/Rack Frame	Novastar	Slim-Line	12 U
28230-011	Aluminum	767 mm	Cabinet/Rack Frame	Novastar	Slim-Line	16 U
28230-070	Aluminum	767 mm	Cabinet/Rack Frame	Novastar	Slim-Line	16 U
28230-130	Aluminum	767 mm	Cabinet/Rack Frame	Novastar	Slim-Line	16 U
28230-190	Aluminum	767 mm	Cabinet/Rack Frame	Novastar	Slim-Line	16 U
28230-191	Aluminum	767 mm	Cabinet/Rack Frame	Novastar	Slim-Line	16 U
28230-015	Aluminum	945 mm	Cabinet/Rack Frame	Novastar	Slim-Line	20 U
28230-074	Aluminum	945 mm	Cabinet/Rack Frame	Novastar	Slim-Line	20 U
28230-134	Aluminum	945 mm	Cabinet/Rack Frame	Novastar	Slim-Line	20 U
28230-194	Aluminum	945 mm	Cabinet/Rack Frame	Novastar	Slim-Line	20 U
28230-195	Aluminum	945 mm	Cabinet/Rack Frame	Novastar	Slim-Line	20 U
28230-020	Aluminum	1167 mm	Cabinet/Rack Frame	Novastar	Slim-Line	25 U
28230-079	Aluminum	1167 mm	Cabinet/Rack Frame	Novastar	Slim-Line	25 U

Catalog Number	Frame Material	Height	ProductType	Product Family	Type	Rack Height
28230-139	Aluminum	1167 mm	Cabinet/Rack Frame	Novastar	Slim-Line	25 U
28230-198	Aluminum	1167 mm	Cabinet/Rack Frame	Novastar	Slim-Line	25 U
28230-199	Aluminum	1167 mm	Cabinet/Rack Frame	Novastar	Slim-Line	25 U
28230-029	Aluminum	1567 mm	Cabinet/Rack Frame	Novastar	Slim-Line	34 U
28230-088	Aluminum	1567 mm	Cabinet/Rack Frame	Novastar	Slim-Line	34 U
28230-148	Aluminum	1567 mm	Cabinet/Rack Frame	Novastar	Slim-Line	34 U
28230-202	Aluminum	1567 mm	Cabinet/Rack Frame	Novastar	Slim-Line	34 U
28230-203	Aluminum	1567 mm	Cabinet/Rack Frame	Novastar	Slim-Line	34 U
28230-033	Aluminum	1745 mm	Cabinet/Rack Frame	Novastar	Slim-Line	38 U
28230-092	Aluminum	1745 mm	Cabinet/Rack Frame	Novastar	Slim-Line	38 U
28230-152	Aluminum	1745 mm	Cabinet/Rack Frame	Novastar	Slim-Line	38 U
28230-206	Aluminum	1745 mm	Cabinet/Rack Frame	Novastar	Slim-Line	38 U
28230-207	Aluminum	1745 mm	Cabinet/Rack Frame	Novastar	Slim-Line	38 U
28230-048	Aluminum	1967 mm	Cabinet/Rack Frame	Novastar	Slim-Line	43 U
28230-097	Aluminum	1967 mm	Cabinet/Rack Frame	Novastar	Slim-Line	43 U
28230-157	Aluminum	1967 mm	Cabinet/Rack Frame	Novastar	Slim-Line	43 U
28230-210	Aluminum	1967 mm	Cabinet/Rack Frame	Novastar	Slim-Line	43 U
28230-211	Aluminum	1967 mm	Cabinet/Rack Frame	Novastar	Slim-Line	43 U
28230-042	Aluminum	2145 mm	Cabinet/Rack Frame	Novastar	Slim-Line	47 U
28230-101	Aluminum	2145 mm	Cabinet/Rack Frame	Novastar	Slim-Line	47 U

Catalog Number	Frame Material	Height	ProductType	Product Family	Type	Rack Height
28230-162	Aluminum	2145 mm	Cabinet/Rack Frame	Novastar	Slim-Line	47 U
28230-214	Aluminum	2145 mm	Cabinet/Rack Frame	Novastar	Slim-Line	47 U
28230-215	Aluminum	2145 mm	Cabinet/Rack Frame	Novastar	Slim-Line	47 U

Table 2/2					
Catalog Number	Width	Depth	Color	Color Code	Static Load
28230-001	553 mm	500 mm	Black Grey	RAL 7021	200 kgf
28230-060	553 mm	600 mm	Black Grey	RAL 7021	200 kgf
28230-004	553 mm	500 mm	Black Grey	RAL 7021	200 kgf
28230-063	553 mm	600 mm	Black Grey	RAL 7021	200 kgf
28230-007	553 mm	500 mm	Black Grey	RAL 7021	200 kgf
28230-054	553 mm	900 mm	Black Grey	RAL 7021	200 kgf
28230-055	553 mm	1000 mm	Black Grey	RAL 7021	200 kgf
28230-066	553 mm	600 mm	Black Grey	RAL 7021	200 kgf
28230-126	553 mm	800 mm	Black Grey	RAL 7021	200 kgf
28230-011	553 mm	500 mm	Black Grey	RAL 7021	200 kgf
28230-070	553 mm	600 mm	Black Grey	RAL 7021	200 kgf
28230-130	553 mm	800 mm	Black Grey	RAL 7021	200 kgf
28230-190	553 mm	900 mm	Black Grey	RAL 7021	200 kgf
28230-191	553 mm	1000 mm	Black Grey	RAL 7021	200 kgf
28230-015	553 mm	500 mm	Black Grey	RAL 7021	200 kgf
28230-074	553 mm	600 mm	Black Grey	RAL 7021	200 kgf
28230-134	553 mm	800 mm	Black Grey	RAL 7021	200 kgf
28230-194	553 mm	900 mm	Black Grey	RAL 7021	200 kgf
28230-195	553 mm	1000 mm	Black Grey	RAL 7021	200 kgf
28230-020	553 mm	500 mm	Black Grey	RAL 7021	200 kgf
28230-079	553 mm	600 mm	Black Grey	RAL 7021	200 kgf
28230-139	553 mm	800 mm	Black Grey	RAL 7021	200 kgf
28230-198	553 mm	900 mm	Black Grey	RAL 7021	200 kgf
28230-199	553 mm	1000 mm	Black Grey	RAL 7021	200 kgf
28230-029	553 mm	500 mm	Black Grey	RAL 7021	200 kgf
28230-088	553 mm	600 mm	Black Grey	RAL 7021	200 kgf

CatalogNumber	Width	Depth	Color	Color Code	Static Load
28230-148	553 mm	800 mm	Black Grey	RAL 7021	200 kgf
28230-202	553 mm	900 mm	Black Grey	RAL 7021	200 kgf
28230-203	553 mm	1000 mm	Black Grey	RAL 7021	200 kgf
28230-033	553 mm	500 mm	Black Grey	RAL 7021	200 kgf
28230-092	553 mm	600 mm	Black Grey	RAL 7021	200 kgf
28230-152	553 mm	800 mm	Black Grey	RAL 7021	200 kgf
28230-206	553 mm	900 mm	Black Grey	RAL 7021	200 kgf
28230-207	553 mm	1000 mm	Black Grey	RAL 7021	200 kgf
28230-048	553 mm	500 mm	Black Grey	RAL 7021	200 kgf
28230-097	553 mm	600 mm	Black Grey	RAL 7021	200 kgf
28230-157	553 mm	800 mm	Black Grey	RAL 7021	200 kgf
28230-210	553 mm	900 mm	Black Grey	RAL 7021	200 kgf
28230-211	553 mm	1000 mm	Black Grey	RAL 7021	200 kgf
28230-042	553 mm	500 mm	Black Grey	RAL 7021	200 kgf
28230-101	553 mm	600 mm	Black Grey	RAL 7021	200 kgf
28230-162	553 mm	800 mm	Black Grey	RAL 7021	200 kgf
28230-214	553 mm	900 mm	Black Grey	RAL 7021	200 kgf
28230-215	553 mm	1000 mm	Black Grey	RAL 7021	200 kgf

ADDITIONAL PRODUCT DETAILS

Please order doors, rear panels, side panels, top cover assemblies, plinths, floors, shelves, slide rails and castors or adjustable feet separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER