



## NVENT CADDY CUSHION CLAMP INSULATED STRUT CLAMP FOR PIPE/TUBE



### FEATURES

Fits into open side of strut channel

Plastic cushion is hinged to spread apart for easy installation

Reduces noise and absorbs shock by gripping the pipe/tube firmly

Square neck of carriage bolt prevents over-tightening

Nylon locknut prevents loosening under vibration

FM® Specification Tested (from 3/8" to 4" of Copper Tube Size)

### SPECIFICATIONS

**Material:** Steel;Polypropylene

**Finish:** Zinc Chromate

Table 1/2


Catalog Number	Article Number	Outer Diameter (OD)	Copper Tube Size	Pipe Size	Pipe Size Range	NB/DN
CCC0037	598883	9.5 mm	1/4"			
CCC0050	598884	12.7 mm	3/8"	1/4"	0.25 in	8
CCC0062	598886	15.8 mm	1/2"	3/8"	0.375 in	10
CCC0087	598891	22.2 mm	3/4"	1/2"	0.5 in	15
CCC0075	598888	19.1 mm	5/8"			
CCC0100	598892	25.4 mm		3/4"	0.75 in	20

Catalog Number	Article Number	Outer Diameter (OD)	Copper Tube Size	Pipe Size	Pipe Size Range	NB/DN
CCC0112	598894	28.6 mm	1"			
CCC0125	598895	31.8 mm		1"	1 in	25
CCC0162	598899	41.3 mm	1 1/2"	1 1/4"	1.25 in min	32
CCC0187	598903	47.6 mm		1 1/2"	1.5 in	40
CCC0212	598906	53.9 mm	2"			
CCC0237	598908	60.3 mm		2"	2 in min	50
CCC0450	598957	114.3 mm		4"	4 in	100

Table 2/2

Catalog Number	Article Number	Width (W)	A	B
CCC0037	598883	39.7 mm	18.9 mm	35.4 mm
CCC0050	598884	39.7 mm	22.1 mm	38.6 mm
CCC0062	598886	39.7 mm	25.2 mm	41.7 mm
CCC0087	598891	39.7 mm	31.6 mm	48.1 mm
CCC0075	598888	39.7 mm	28.4 mm	44.9 mm
CCC0100	598892	39.7 mm	34.8 mm	51.3 mm
CCC0112	598894	39.7 mm	39 mm	62.4 mm
CCC0125	598895	39.7 mm	42.1 mm	65.6 mm
CCC0162	598899	39.7 mm	51.6 mm	75.1 mm
CCC0187	598903	39.7 mm	59 mm	81.5 mm
CCC0212	598906	39.7 mm	68.5 mm	91 mm
CCC0237	598908	39.7 mm	74.9 mm	97.4 mm
CCC0450	598957	39.7 mm	132 mm	160.5 mm

## DIAGRAMS

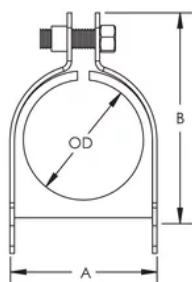

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**