


NVENT CADDY MACROFIX PLUS LF LOW-FRICTION

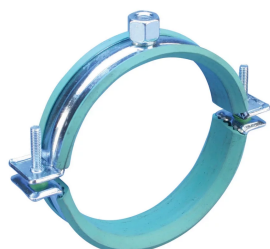

FEATURES

Includes easy closing mechanism

Age resistant lining designed specifically for plastic pipe applications

Low-friction properties allow for expansion, contraction and easy sliding of pipe

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

SPECIFICATIONS

Finish:	Electrogalvanized
Material:	Steel;EPDM-SBR Rubber
Color:	Green
Temperature:	-50 to 110 °C

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	Pipe Size Range	NB/DN	Plastic Pipe Size
MPL016	595035	16 mm	3/8"	0.375 in	10	
MPL020	595036	20 mm	1/2"	0.5 in	15	20mm
MPL025	595037	25 mm	3/4"	0.75 in	20	25mm
MPL032	595038	32 mm	1"	1 in	25	32mm
MPL040	595039	40 mm	1 1/4"	1.25 in min	32	40mm

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	Pipe Size Range	NB/DN	Plastic Pipe Size
MPL050	595040	50 mm	1 1/2"	1.5 in	40	50mm
MPL063	595042	63 mm	2"	2 in min	50	63mm
MPL075	595043	75 mm	2 1/2"	2.5 in	65	75mm
MPL090	595044	90 mm	3"	3 in	80	90mm
MPL110	595045	110 mm	4"	4 in	100	100mm
MPL125	595046	125 mm				110mm
MPL160	595048	160 mm				160mm


Table 2/2

Catalog Number	Article Number	Rod Size (RS)	Width (W)	Thickness (T)	Static Load (F)
MPL016	595035	8, 10	30 mm	1.5 mm	1125N
MPL020	595036	8, 10	30 mm	1.5 mm	1125N
MPL025	595037	8, 10	30 mm	1.5 mm	1125N
MPL032	595038	8, 10	30 mm	1.5 mm	1125N
MPL040	595039	8, 10	30 mm	1.5 mm	1125N
MPL050	595040	8, 10	30 mm	2 mm	1725N
MPL063	595042	8, 10	30 mm	2 mm	1725N
MPL075	595043	8, 10	30 mm	2 mm	1725N
MPL090	595044	8, 10	30 mm	2 mm	1725N
MPL110	595045	8, 10	30 mm	2.5 mm	2000N
MPL125	595046	8, 10	30 mm	2.5 mm	2000N
MPL160	595048	8, 10	30 mm	2.5 mm	2000N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

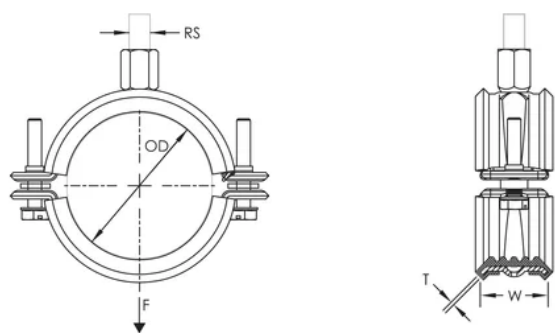

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER