



NVENT CADDY SPEED LINK Y-TOGGLE WITH EYELET EXTENSION



CERTIFICATIONS



FEATURES

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Y-design provides improved stability

SPECIFICATIONS


Table 1/2						
Catalog Number	Article Number	Material	Finish	Static Load Safety Factor	Wire Rope Diameter	Wire Rope "Y" Length (YL)
SLD15Y500	195960	Steel	Electrogalvanized	5:1	1.5 mm	0.5m

Table 2/2					
Catalog Number	Article Number	A	B	Static Load (F)	Packing Quantity
SLD15Y500	195960	39 mm	5 mm	195N	1.0000

ADDITIONAL PRODUCT DETAILS

nVent CADDY Speed Link locking device not included.

DIAGRAMS

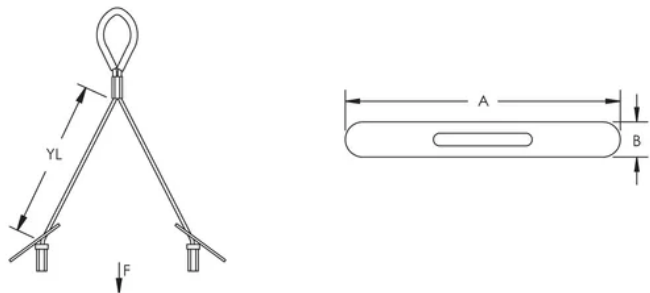

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500