



# NVENT CADDY PYRAMID ST FIXED STRUT SUPPORT



## CERTIFICATIONS



## FEATURES

- Provides superior support for pipe, conduit, cable tray and equipment
- Foam bottom offers low abrasion interface for better roof membrane protection
- Compatible with roof surfaces including single ply, bituminous, metal and spray foam
- Provides superior load distribution, even with varying rooftop surfaces
- Ready to use out of the box, saving installation time and labor
- Multiple sizes and load ratings offer the ability to tailor the solution to the application
- Easy to transport to the roof
- Hot-dip galvanized and UV stabilized for long lasting performance

## SPECIFICATIONS

<b>Static Load Safety Factor:</b>	3:1
<b>Finish:</b>	Hot-Dip Galvanized
<b>Material:</b>	Polyethylene;Polypropylene;Steel
<b>Temperature:</b>	-45 to 65 °C

Table 1/2

Catalog Number	Article Number	E-Number	Length 1 (L1)	Length 2 (L2)	Height (H)	Width (W)
PSF6C	360463	1653295	152 mm	203 mm	122 mm	152 mm
PSF10C	360464	1653296	254 mm	317.5 mm	122 mm	203 mm
PSF10D	360465	1653297	254 mm	317.5 mm	163 mm	203 mm
PSF16C	360466	1653303	406 mm	483 mm	122 mm	203 mm
PSF16D	360467	1653304	406 mm	483 mm	163 mm	203 mm


Table 2/2

Catalog Number	Article Number	E-Number	Surface Area	Unit Weight	Static Load (F)	Certifications
PSF6C	360463	1653295	26452mm <sup>2</sup>	0.5 kg	1334N	
PSF10C	360464	1653296	59355mm <sup>2</sup>	1 kg	4450N	ITB
PSF10D	360465	1653297	59355mm <sup>2</sup>	1.5 kg	4450N	ITB
PSF16C	360466	1653303	91613mm <sup>2</sup>	1.5 kg	6670N	ITB
PSF16D	360467	1653304	91613mm <sup>2</sup>	2 kg	6670N	ITB

## ADDITIONAL PRODUCT DETAILS

Static load at 73.1 kPa (10.6 psi) roof loading. Contact project or roofing engineer for maximum allowable load on individual project roof system.

## DIAGRAMS

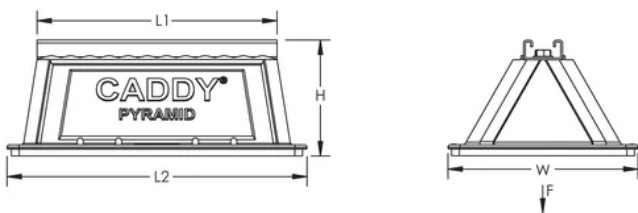

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**