

MULTI-FUNCTION C-CLAMP



FEATURES

Multi-functional beam clamp

Use with Cable/Conduit/Pipe Clamp or Square Washer for Multi-Function C-Clamp

SPECIFICATIONS

Finish: Hot-Dip Galvanized

Table 1/2

| Catalog Number | Article Number | Material | Flange Thickness (FT) | Hole Size (HS) | Screw Diameter (Sc) | Screw Length (L) |
|----------------|----------------|---------------------------------|-----------------------|----------------|---------------------|------------------|
| C20HD | 336100 | Steel | 4 - 20 mm | 14 mm | 6 | 25mm |
| C20S4 | 336130 | Stainless Steel 304 (EN 1.4301) | 4 - 20 mm | 14 mm | 6 | 25mm |
| C30HD | 336110 | Steel | 17 - 30 mm | 14 mm | 8 | 30mm |
| C30S4 | 336140 | Stainless Steel 304 (EN 1.4301) | 17 - 30 mm | 14 mm | 8 | 30mm |
| C45HD | 336120 | Steel | 30 - 44 mm | 14 mm | 8 | 30mm |
| C45S4 | 336150 | Stainless Steel 304 (EN 1.4301) | 30 - 44 mm | 14 mm | 8 | 30mm |

Table 2/2


| Catalog Number | Article Number | Torque (TQ) | Static Load (F) |
|----------------|----------------|-------------|-----------------|
| C20HD | 336100 | 3 N·m | 1100N |

| Catalog Number | Article Number | Torque (TQ) | Static Load (F) |
|----------------|----------------|-------------|-----------------|
| C20S4 | 336130 | 3 N·m | 1100N |
| C30HD | 336110 | 3 N·m | 1100N |
| C30S4 | 336140 | 3 N·m | 1100N |
| C45HD | 336120 | 3 N·m | 1100N |
| C45S4 | 336150 | 3 N·m | 1100N |

ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

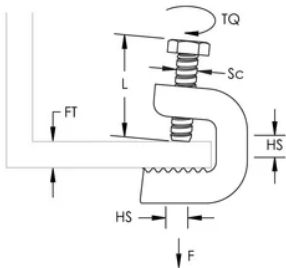

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER