

## BRANCH LINE RESTRAINT STRUCTURE ATTACHMENT TO THREADED HOLE



### CERTIFICATIONS



### FEATURES

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to concrete anchors or structural attachments with female threads

Can be used for bolting through steel

### SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2

Catalog Number	Article Number	Length (L)	Rod Size (RS)	Screw Diameter (Sc)	Height (H)	Screw Length (L)
CSBBRS3EG		40.4mm	0.375, 0.5	0.375	28.2mm	19mm
CSBBRS3MEG	402241	40.4mm	10, 12	10	28.2mm	19mm

Table 2/2


Catalog Number	Article Number	Width (W)	Certifications
----------------	----------------	-----------	----------------

CSBBRS3EG		26.9mm	UL, OSHPD/HCAI, FM Approved, Seismic
CSBBRS3MEG	402241	26.9mm	AON Fire Protection, Rigid Seismic, UL, FM Approved, Seismic

### ADDITIONAL PRODUCT DETAILS

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

### DIAGRAMS

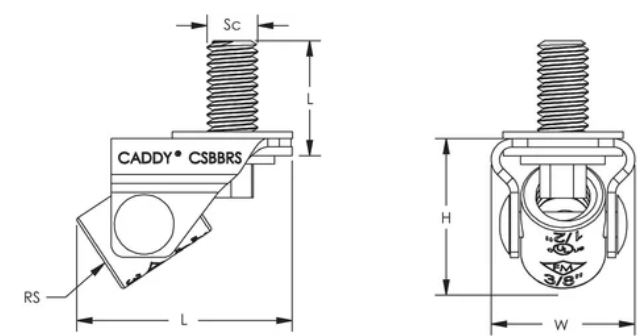

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.