 


DISCONNECTING LINK WITH ENCLOSURE FOR CABLE, BARE COPPER

CATALOG NUMBER

DLCBX95



FEATURES

Allows for quick and easy disconnection of the earthing system to facilitate testing of the earth in isolation

High conductivity, hard drawn, electrolytic tough pitch copper per EN 13601

Includes stainless steel 304 enclosure, rubber dustproof, halogen-free polyamide insulators, stainless steel hardware

Compression straight lug: according to DIN46235 standard

Rubber gland for cable connection

8 microns tinned finish according to ASTM B545 Service Class "C"

PRODUCT ATTRIBUTES

Material: Stainless Steel 304 (EN 1.4301); Copper

Finish: Bare

A: 90mm

Diameter (Ø): 20mm

Height (H): 66.5mm

Thickness (T): 4mm

Thread Size (TS): M8

Length 1 (L1): 125mm

Length 2 (L2): 230mm

Length 3 (L3): 210mm

Length 4 (L4): 160mm

Width 1 (W1): 40mm

Width 2 (W2): 150mm


Width 3 (W3): 170mm

Unit Weight: 1.45kg

ADDITIONAL PRODUCT DETAILS

Available cable size $\leq 95 \text{ mm}^2$.

DIAGRAMS

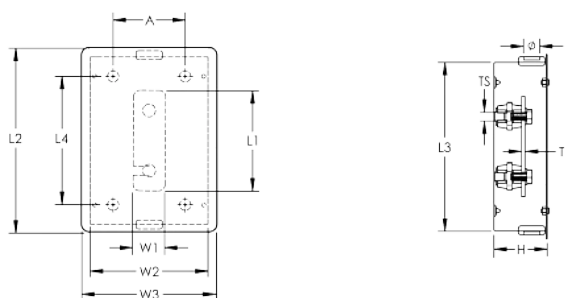

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER