



115 STANDARD DUTY LOOP HANGER



The 115 Standard Duty Loop Hanger is ideal for suspending stationary, non-insulated pipe lines, including CPVC pipes, in fire sprinkler systems. A knurled insert nut helps simplify vertical adjustments and flared edges on the base (1/2" to 4" sizes) help protect pipes from coming into contact with any sharp edges of the hanger.

CERTIFICATIONS



FEATURES

- Flared edges help prevent any sharp surfaces from coming into contact with the pipe (1/2" to 4" sizes)
- Retained insert nut helps ensure the loop hanger and insert nut stay together
- Recommended for the suspension of stationary non-insulated pipe lines
- Manufactured to use the minimum rod size permitted by NFPA® for fire sprinkler piping
- Conforms with Federal Specification WW-H-171 (Type 10), Manufacturers Standardization Society (MSS) SP-58 (Type 10)

SPECIFICATIONS

- Finish:** Pregalvanized
- Material:** Steel


Table 1/2						
Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	A	B	C
1150050EG	1/2"	0.84"	3/8"	2 13/16"	1 1/8"	1"
1150075EG	3/4"	1.05"	3/8"	3"	1 3/16"	15/16"

Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size(RS)	A	B	C
1150100EG	1"	1.31"	3/8"	3 1/4"	1 3/8"	15/16"
1150125EG	1 1/4"	1.66"	3/8"	3 9/16"	1 1/2"	15/16"
1150150EG	1 1/2"	1.9"	3/8"	3 13/16"	1 5/8"	15/16"
1150200EG	2"	2 3/8"	3/8"	4 1/4"	1 7/8"	15/16"
1150250EG	2 1/2"	2 7/8"	3/8"	5 15/16"	3 7/16"	2"
1150300EG	3"	3 1/2"	3/8"	6 9/16"	3 1/2"	1 15/16"
1150350EG	3 1/2"	4"	3/8"	7 1/16"	3 3/4"	1 15/16"
1150400EG	4"	4 1/2"	3/8"	7 9/16"	4"	1 15/16"
1150500EG	5"	5 9/16"	1/2"	9 13/16"	4 3/4"	2 1/4"
1150600EG	6"	6 5/8"	1/2"	11 5/16"	6 5/16"	3 5/16"
1150800EG	8"	8 5/8"	1/2"	12 7/8"	6 7/8"	2 7/8"

Table 2/2

Catalog Number	Certifications
1150050EG	cUL, UL
1150075EG	cUL, FM Approved, Pipe Hanger Components, UL
1150100EG	cUL, FM Approved, Pipe Hanger Components, UL
1150125EG	cUL, FM Approved, Pipe Hanger Components, UL
1150150EG	cUL, FM Approved, Pipe Hanger Components, UL
1150200EG	cUL, FM Approved, Pipe Hanger Components, UL
1150250EG	cUL, FM Approved, Pipe Hanger Components, UL
1150300EG	cUL, FM Approved, Pipe Hanger Components, UL
1150350EG	cUL, FM Approved, Pipe Hanger Components, UL
1150400EG	cUL, FM Approved, Pipe Hanger Components, UL
1150500EG	cUL, FM Approved, Pipe Hanger Components, UL
1150600EG	cUL, FM Approved, Pipe Hanger Components, UL
1150800EG	cUL, FM Approved, Pipe Hanger Components, UL

DIAGRAMS

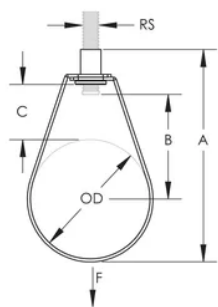

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER