



# IMPROVED NVENT CADDY CAT HP J-HOOK MOD CLIP WITH BC200 BEAM CLAMP



The Improved nVent CADDY Cat HP Mod Clip J-Hook with BC200 Beam Clamp eliminates the need for screws, rivets, or special tools—significantly cutting down installation time and expense. Contractors gain a secure hold on J-Hooks, boosting stability and flexibility on-site while minimizing inventory impact.

## CERTIFICATIONS




## FEATURES

- Easy beam flange installation
- Tool-free assembly
- Works with nVent J-Hook Versa-Mount technology from nVent CADDY

## SPECIFICATIONS

Table 1/1				
Catalog Number	Finish	Material	Flange Thickness (FT)	Static Load (F)
CATHPMBC200	Electrogalvanized, nVent CADDY Armour	Steel, Spring Steel	0.125" - 0.625"	100 lb

DIAGRAMS

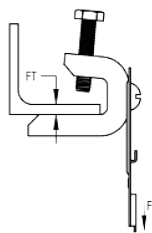

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**